

Molded Case Circuit Breakers Q-Line Circuit Breakers

Bolt-on Circuit Breakers
240V Class

Section 3

THQB and THHQB 120/240 Vac Arc Fault (Single pole)

# of Poles	Ampere Rating	Wire Range ¹	120/240 Vac Interrupting Rating	Product Number	List Price GO-133
1	15	14-10 Cu/14-10 Al	10kA	THQB1115AF	\$155.00
1	20	14-10 Cu/14-10 Al	10kA	THQB1120AF	\$155.00
1	15	14-10 Cu/14-10 Al	22kA	THHQB1115AF	\$272.00
1	20	14-10 Cu/14-10 Al	22kA	THHQB1120AF	\$272.00
2	15	14-10 Cu/14-10 Al	10kA	THQB2115AF	\$305.00
2	20	14-10 Cu/14-10 Al	10kA	THQB2120AF	\$305.00
2	15	14-10 Cu/14-10 Al	22kA	THHQB2115AF	\$535.00
2	20	14-10 Cu/14-10 Al	22kA	THHQB2120AF	\$535.00

THQB, THHQB 120 Vac, Ground Fault Breakers (5 ma)

# of Poles	Ampere Rating	Wire Range ¹	120 Vac Interrupting Rating	Product Number	List Price GO-133
1	15	14-8 Cu/12-8 Al	10kA	THQB1115GF	\$120.00
1	20	14-8 Cu/12-8 Al	10kA	THQB1120GF	\$120.00
1	30	14-8 Cu/12-8 Al	10kA	THQB1130GF	\$120.00
1	15	14-8 Cu/12-8 Al	22kA	THHQB1115GF	\$235.00
1	20	14-8 Cu/12-8 Al	22kA	THHQB1120GF	\$235.00
1	30	14-8 Cu/12-8 Al	22kA	THHQB1130GF	\$235.00

THQB 120/240 or 208Y/120 Vac, Ground Fault Breakers (5 ma), Internal Common Trip

# of Poles	Ampere Rating	Wire Range ¹	120/240 or 208Y/120 Vac Interrupting Rating	Product Number	List Price GO-133
2	15	14-8 Cu/12-8 Al	10kA	THQB2115GF	\$212.00
2	20	14-8 Cu/12-8 Al	10kA	THQB2120GF	\$212.00
2	30	14-8 Cu/12-8 Al	10kA	THQB2130GF	\$212.00

THQB 120 Vac, Equipment Protection Ground Fault Circuit Breakers (30 ma)

# of Poles	Ampere Rating	Wire Range ¹	120 Vac Interrupting Rating	Product Number	List Price GO-133
1	15	14-8 Cu/12-8 Al	10kA	THQB1115GFEP	\$205.00
1	20	14-8 Cu/12-8 Al	10kA	THQB1120GFEP	\$205.00
1	30	14-8 Cu/12-8 Al	10kA	THQB1130GFEP	\$205.00

THQB 120/240 or 208Y/120 Vac, Ground Fault Breakers Equipment Protection (30 ma) Ground Fault Circuit Breakers, Internal Common Trip

# of Poles	Ampere Rating	Wire Range ¹	120/240 or 208Y/120 Vac Interrupting Rating	Product Number	List Price GO-133
2	15	14-8 Cu/12-8 Al	10kA	THQB2115GFEP	\$273.00
2	20	14-8 Cu/12-8 Al	10kA	THQB2120GFEP	\$273.00
2	30	14-8 Cu/12-8 Al	10kA	THQB2130GFEP	\$273.00


THQB, THHQB 120/240 Vac, High Intensity Discharge Lighting Loads³

# of Poles	Ampere Rating	Wire Range ¹	120/240 Vac Interrupting Rating	Product Number	List Price GO-135B
1	15	14-8 Cu/12-8 Al	10kA	THQB1115HID ²	\$23.75
1	20	14-8 Cu/12-8 Al	10kA	THQB1120HID ²	\$23.75
1	25	14-8 Cu/12-8 Al	10kA	THQB1125HID	\$23.75
1	30	14-8 Cu/12-8 Al	10kA	THQB1130HID	\$23.75
1	15	14-8 Cu/12-8 Al	22kA	THHQB1115HID ²	\$41.50
1	20	14-8 Cu/12-8 Al	22kA	THHQB1120HID ²	\$41.50
1	25	14-8 Cu/12-8 Al	22kA	THHQB1125HID	\$47.00
1	30	14-8 Cu/12-8 Al	22kA	THHQB1130HID	\$47.00
2	15	14-8 Cu/12-8 Al	10kA	THQB2115HID	\$52.50
2	20	14-8 Cu/12-8 Al	10kA	THQB2120HID	\$52.50
2	25	14-8 Cu/12-8 Al	10kA	THQB2125HID	\$52.50
2	30	14-8 Cu/12-8 Al	10kA	THQB2130HID	\$52.50

¹Solid or stranded for 14-10 AWG.

²UL listed as SWD (switching duty). Suitable for switching 120 Vac fluorescent lighting loads.

³UL listed as HID (high intensity discharge).

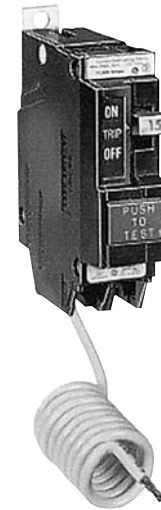

THQB1115GF



Residential Load Centers

PowerMark Gold and Plus Load Centers

Product Number Guides

Section 1

Product Number Guide for Load Centers

(Product number for illustrative purposes only)

T	M	42	4	20	C	CU	B
----------	----------	-----------	----------	-----------	----------	-----------	----------

GE Identification

Type

- M = Main breaker
- L = Main lug
- LM = Convertible
- PL = Main lug (Thermoplastic)

Maximum Number 1" Spaces

2, 4, 6...42

Insert for 3-Phase 4-Wire Load Centers

Insert for Specials

- G or T = Factory installed ground bar
- B = Bottom feed main breaker
- FL = Factory installed feed-through lugs
- D = Optional door for 6-8 circuit panel. (Doors standard on all units 12 circuits or greater)

Insert for PowerMark Gold

- CU = Copper Bus
- 42 = Copper Bus Full 42 circuit panel

Enclosure Type

- C = Combination surface/flush
- F = Flush
- S = Surface
- R = Outdoor

Bus Ampere Rating

40 = 40 Amps	20 = 200 Amps
70 = 70 Amps	22 = 225 Amps
10 = 100 Amps	30 = 300 Amps
12 = 125 Amps	40 = 400 Amps
15 = 150 Amps	60 = 600 Amps

Product Number Guide for Q-Line Plug-in Circuit Breakers

(Product number for illustrative purposes only)

T	H	QL	1	1*	15	
----------	----------	-----------	----------	-----------	-----------	---------

GE Identification

Interrupting Rating

- H = 10kAIC
- HH = 22kAIC
- X = 65kAIC

Type

- QL = 1" plug-in
- QP = 1/2" plug-in
- QB = 1" bolt-on

Poles (1, 2, 3)

Ground Fault/Arc Fault Circuit Interrupter

- GF = 1-pole Ground Fault Circuit Interrupter-5 mA
- GF1= 2-pole Ground Fault Circuit Interrupter-5 mA
- AF = 1- & 2-pole Arc Fault Circuit Interrupter
- GFEP = 1- & 2-pole Ground Fault Circuit Interrupter-30 mA

Ampere Rating

Voltage

- 1 = 120/240V
- 2 = 240V

*Omit character for THQP breakers, which are all 120/240V.

