


C-Clamp – 2000037EG



- Pressed steel beam clamp
- Conforms with Federal Specification WW-H-171 (Type 23), Manufacturers Standardization Society ANSI®/MSS-SP-58 (Type 23)

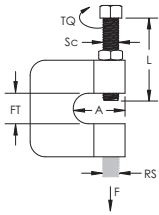

Part Number	2000037EG
Material	Steel
Finish	Electrogalvanized
Static Load Safety Factor	3.5:1
Rod Size (RS)	3/8"
Flange Thickness (FT)	3/4" Max
A	1 1/8"
Screw Diameter (Sc)	3/8"
Screw Length (L)	1 1/4"
Pipe Size	4" Max
Torque (TQ)	5 ft lb
Static Load (F)	250 lb
Standard Packaging Quantity	100 pc
UPC	78285633963

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

Recognizing that torque wrenches are generally not used or available on many job sites, the setscrew should be tightened so it contacts the I-beam and then an additional 1/4 to 1/2 turn added.

ANSI is a registered trademark of American National Standards Institute.

WARNING

ERICO products shall be installed and used only as indicated in ERICO's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your ERICO customer service representative. Improper installation, misuse, misapplication or other failure to completely follow ERICO's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death.

Copyright © 2015 ERICO International Corporation. All rights reserved.

CADDY, CADWELD, CRITEC, ERICO, ERIFLEX, ERITECH, and LENTON are registered trademarks of ERICO International Corporation.

