
 
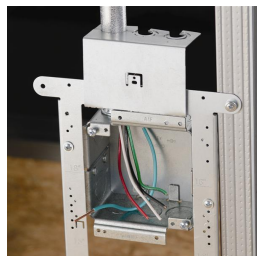


# CADDY ALL-IN-ONE Floor-Mounted Without Mud Ring – A1FF0GTC



- Preset to a finish height of 18" from the floor (adjustable to 12" or 15")
- Integrated first means of support accepts conduit or MC/AC cable
- Provides the flexibility to add a mud ring for non-standard drywall thicknesses
- Box remains fixed in place when mud ring is removed
- Accommodates additional CADDY ALL-IN-ONE box assemblies, support brackets and low-voltage mounting plates
- Includes multiple 1/2" and 3/4" knockouts on each side of the box
- Works with standard US and Canadian mud rings

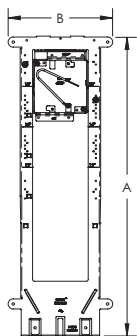

Part Number	A1FF0GTC
Material	Steel
Finish	Pregalvanized
EMT Conduit Size	1/2" 3/4"
MC/AC Cable Size	14-2 to 12-3
Knockout Sizes	{8} 1/2", 3/4" {3} 1/2"
Ground Wire Included	Yes
Box Volume	32.8 in <sup>3</sup>
Depth [D]	3 5/8"
A	22 3/16"
B	7 3/4"
C	2 11/16"



Part Number	A1FF0GTC
Certifications	cULus
Standard Packaging Quantity	5 pc
UPC	78285679490

Ground wire pigtail is 10".

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

**WARNING**

Pentair products shall be installed and used only as indicated in Pentair's product instruction sheets and training materials. Instruction sheets are available at [erico.pentair.com](http://erico.pentair.com) and from your Pentair customer service representative. Improper installation, misuse, misapplication or other failure to completely follow Pentair's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2017 Pentair All rights reserved  
Pentair, CADDY, CADWELD, CRITEC, ERICO, ERIFLEX, ERITECH and LENTON are owned by Pentair or its global affiliates.  
All other trademarks are the property of their respective owners. Pentair reserves the right to change specifications without prior notice.

