

RWF | PULSAIR™

WALL FAN HEATER



THE CLASSIC FAN HEATER

You won't find anything better than this efficient, durable and noise-free forced-air heater. The PULSAIR is extremely popular for many reasons. First, it can be recessed or surface mounted with a surface adapter (optional). It can also be mounted vertically or horizontally so that air can flow either up and down or right and left. Finally, the slim-line PULSAIR can be recessed into a wall thickness of 2 in. to 3 in. While it's a winning heating solution for hallways or bathrooms, it can also be installed anywhere in the house, such as the office, or in commercial spaces. Its nichrome element provides instant heat. Available from 500 W to 2000 W, and from 120 V to 347 V, the PULSAIR is recognized and recommended by those in the know.

VERY QUIET FAN HEATER

THE MOST RESISTANT GRILLE ON THE MARKET

INSTANT HEAT NICHROME ELEMENT

MULTIPLE INSTALLATION OPTIONS RECESSED, SURFACE MOUNTED, HORIZONTAL OR VERTICAL

ADAPTS TO MULTIPLE MARKETS AVAILABLE IN: 120 V, 208 V, 240 V AND 347 V

COLOURS

- **standard:** white, soft white
- **ORORA (optional):** refer to www.stelpro.com/en-CA/orora

FINISH

- epoxy-polyester powdercoat

MANUFACTURING

- 20-gauge steel cabinet and 18-gauge steel grille
- quiet fan – 40 CFM (500 W to 1000 W models) – 75 CFM (1250 W to 2000 W models)
- thermal protection with automatic reset

ELEMENT

- nichrome element produces instant heat

CONTROL

- built-in thermostat (optional)
- wall thermostat (not included) – the use of an electronic thermostat is strongly recommended


INSTALLATION

- wall mounted
- recessed (wall must have a depth of 2 3/8 in. minimum)
- surface mounted with surface adapter (optional)
- four installation positions

WARRANTY

- five years

FOUR INSTALLATION OPTIONS

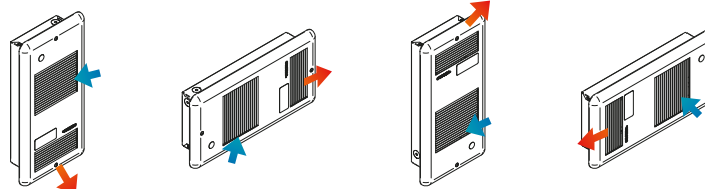

IDEAL FOR:

hallway, bathroom, locker room, office



°STELPRO reserves the right to modify descriptions, manufacturing specifications or prices without prior notice. No returns accepted on optional-colour products. For all the latest models and prices, please refer to our website at www.stelpro.com.




TECHNICAL SPECIFICATIONS

WITHOUT CONTROL		BUILT-IN THERMOSTAT		24 V CONTROL		POWER	VOLTAGE	FLOW	THROW DISTANCE		HEAT RISE		WEIGHT	
CODE	PRICE	CODE	PRICE	CODE	PRICE	WATTS	VOLTS	CFM	M	FT.	°C	°F	KG	LB
RWF0501	149.00	---	---	---	---	500	120	40	2	6'6"	30	54	2.7	6
RWF0508	149.00	---	---	---	---	500	208	40	2	6'6"	30	54	2.7	6
RWF0502	149.00	---	---	---	---	500/375	240/208	40	2	6'6"	30	54	2.7	6
RWF0503	189.00	RWF0503T	219.00	RWF0503C24	234.00	500	347	40	2	6'6"	30	54	2.7	6
RWF0751	158.00	---	---	---	---	750	120	40	2	6'6"	67	121	2.7	6
RWF0758	158.00	---	---	---	---	750	208	40	2	6'6"	67	121	2.7	6
RWF0752	158.00	---	---	---	---	750/563	240/208	40	2	6'6"	67	121	2.7	6
RWF0753	198.00	RWF0753T	228.00	RWF0753C24	243.00	750	347	40	2	6'6"	67	121	2.7	6
RWF1001	160.00	---	---	---	---	1000	120	40	2	6'6"	76	136	2.7	6
RWF1008	160.00	---	---	---	---	1000	208	40	2	6'6"	76	136	2.7	6
RWF1002	160.00	---	---	---	---	1000/750	240/208	40	2	6'6"	76	136	2.7	6
RWF1003	200.00	RWF1003T	230.00	RWF1003C24	245.00	1000	347	40	2	6'6"	76	136	2.7	6
RWF1251	169.00	---	---	---	---	1250	120	75	2.1	6'10"	65	117	2.7	6
RWF1258	169.00	---	---	---	---	1250	208	75	2.1	6'10"	65	117	2.7	6
RWF1252	169.00	---	---	---	---	1250/938	240/208	75	2.1	6'10"	65	117	2.7	6
RWF1253	209.00	RWF1253T	239.00	RWF1253C24	254.00	1250	347	75	2.1	6'10"	65	117	2.7	6
RWF1501	173.00	---	---	---	---	1500	120	75	2.1	6'10"	79	141	2.7	6
RWF1508	173.00	---	---	---	---	1500	208	75	2.1	6'10"	79	141	2.7	6
RWF1502	173.00	---	---	---	---	1500/1125	240/208	75	2.1	6'10"	79	141	2.7	6
RWF1503	213.00	RWF1503T	243.00	RWF1503C24	258.00	1500	347	75	2.1	6'10"	79	141	2.7	6
---	---	---	---	---	---	2000	120	75	2.1	6'10"	111	199	2.7	6
RWF2002	187.00	---	---	---	---	2000/1500	240/208	75	2.1	6'10"	111	199	2.7	6
RWF2008	187.00	---	---	---	---	2000	208	75	2.1	6'10"	111	199	2.7	6
RWF2003	227.00	RWF2003T	257.00	RWF2003C24	272.00	2000	347	75	2.1	6'10"	111	199	2.7	6

Add W for white or SW for soft white (consult the optional colours chart or contact your °STELPRO representative for all other colours).
 --- not available

TECHNICAL DRAWINGS

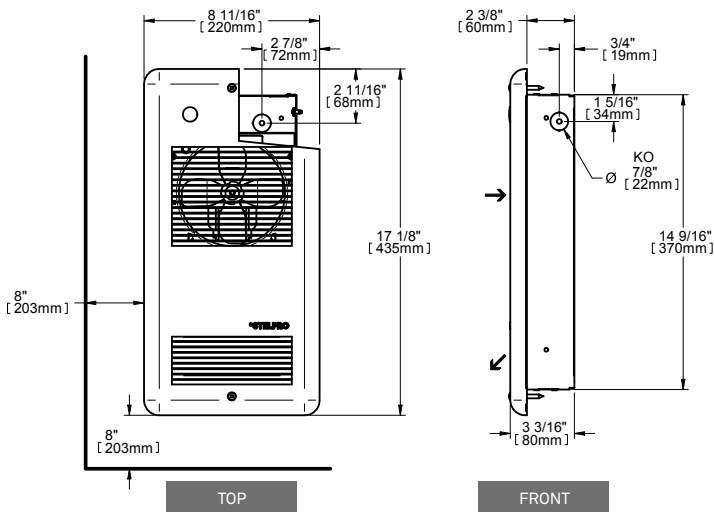

ACCESSORIES

PRODUCT	DESCRIPTION	PRICE
RWFT1**	built-in single pole thermostat [120 V-347 V]	29.00
RWFT2*	built-in double pole thermostat [120 V-347 V]	41.00
RWFSAW	surface adapter (white)	40.00
RWFSASW	surface adapter (soft white)	40.00

* Add W for white or SW for soft white.

* Supplied with a white knob (with a white grille) and a soft white knob (with a soft white grille)

