

## XTP®

.....

The Marrette® XTP® is a high quality, twist-on wire connector with a unique spring and cap grip design that sets it apart from the competition.


### External Cap

- Made of tough, durable polypropylene and 105°C rated to withstand high installation pressures.
- Posi-Grip® surface combines a matte finish with closely-spaced, deep grooves for superior twisting power, even when hands are greasy or damp.
- Deep, wide throat ensures full insulation coverage.
- Threaded entry helps guide large wire bundles into the spring chamber.
- Colour-coded for quick and easy size selection.



### Inner Spring

- Exclusive Live Action® variable volume spring expands to accommodate more wires with less twisting effort, compared to other connectors with a “fixed spring” design.
- Models nos. 329 and 330 have a round spring, while 331, 333 and 335 have a square wire spring construction that gives a positive conductor bite to solid or stranded wires.
- Unique copper-coated spring helps resist corrosion.
- Models nos. 329 and 330 are approved for circuits up to 300V only. — Models nos. 331, 333, 335 and 822 are approved for circuits up to 600V, and lighting fixtures and signs up to 1000V.
- For copper conductor only.
- Convenient packaging - sized right and job-site ready!

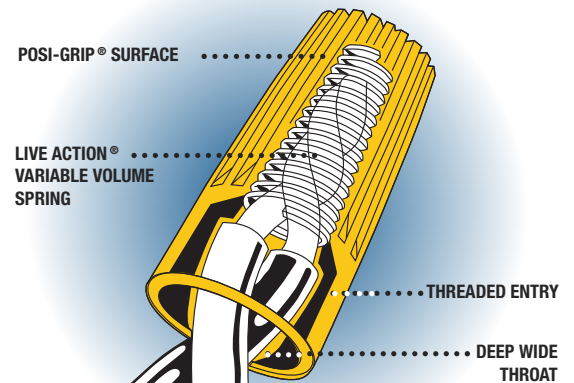

## XTP®

### Ordering Information

Model	Colour	AWG Wire Range								
		22	20	18	16	14	12	10	8	
<b>329</b>	grey	Min.: 1 #22 + 1 #20		Max.: 2 #22 + 3 #20						
<b>330</b>	blue	Min.: 1 #22 + 1 #20		Max.: 3 #16						
<b>331</b>	orange			Min.: 2 #18		Max.: 3 #14				
<b>333</b>	yellow			Min.: 2 #18 + 1 #14		Max.: 2 #14 + 1 #10				
<b>335</b>	red	Min.: 1 #22 + 2 #18		Max.: 1 #14 + 4 #12						
<b>822*</b>	blue	Min.: 2 #22 + 1 #20		Max.: 2 #8						
<b>DRIVERS</b>										
<b>TOOL 331</b>	Plastic driver to install Model 331 (included in all packs of 1000 units + )									
<b>TOOL 333</b>	Plastic driver to install Model 333 and 822 (included in all packs of 1000 units + )									
<b>TOOL 335</b>	Plastic driver to install Model 335 (included in all packs of 1000 units + )									

Note: Refer to pages A23 to A26 and A28 to A29 for related Wire Combination Reference Guides

\*UL not applicable.

### Packaging Options



	Cat. No.	Packaging Format	Quantity per Package	Std. Pkg. (Min./Mult.)
<b>329</b>	329P	Propak	100	1,000 Units
	329BP	Bulk Box	1,000	1,000 Units
	329BK	Flip-Pak	10,000	10,000 Units
<b>330</b>	330P	Propak	100	1,000 Units
	330BP	Bulk Box	1,000	1,000 Units
	330BK	Flip-Pak	10,000	10,000 Units
<b>331</b>	331C	Card (Retail market only*)	20/Card	20 Cards
	331B	Window Box (Retail market only*)	50/Box	10 Boxes
	331P	Propak	100	1,000 Units
	331D	Flip-Pak	500	2,000 Units
	331KP	Resealable Bag	500	5,000 Units
	331M	Flip-Pak	1,000	1,000 Units
	331BK	Flip-Pak	10,000	10,000 Units
	331BAR	Barrel	45,000	45,000 Units
<b>333</b>	333C	Card (Retail market only*)	15/Card	20 Cards
	333B	Window Box (Retail market only*)	50/Box	10 Boxes
	333P	Propak	100	1,000 Units
	333KP	Resealable Bag	500	5,000 Units
	333D	Flip-Pak	500	500 Units
	333M	Flip-Pak	1,000	1,000 Units
	333BK	Flip-Pak	10,000	10,000 Units
	333BAR	Barrel	25,000	25,000 Units
<b>335</b>	335C	Card (Retail market only*)	6/Card	20 Cards
	335B	Window Box (Retail market only*)	25/Box	10 Boxes
	335P	Propak	100	1,000 Units
	335Q	Flip-Pak	200	800 Units
	335D	Flip-Pak	500	500 Units
	335BK	Flip-Pak	7,000	7,000 Units
<b>822</b>	822Q	Flip-Pak	200	800 Units
	822D	Flip-Pak	500	500 Units
	822BK	Flip-Pak	8,000	8,000 Units
	822BAR	Barrel	20,000	20,000 Units

\* Retail: Order 1 each for one (1) Card/Box/Flip-Pak