

EMT

Set-Screw Fittings



**CI5404 / CI5408
CI5404IT / CI5408IT**



**CI5410 / CI5432
CI5410IT / CI5432IT**



Cat. No.		Trade Size (in.)
Regular	Insulated	
EMT Set-Screw Fittings (Steel)		
CI5404	CI5404-IT	1/2
CI5406	CI5406-IT	3/4
CI5408	CI5408-IT	1
CI5410	CI5410-IT	1-1/4
CI5412	CI5412-IT	1-1/2
CI5416	CI5416-IT	2
CI5420	CI5420-IT	2-1/2
CI5424	CI5424-IT	3
CI5432	CI5432-IT	4

Concrete-tight

**CI5004 (-IT) /
CI5008 (-IT)**



Zinc Die Cast Locknut
IT: with insulated throat.

**CI5010 (-IT) /
CI5016 (-IT)**



Zinc Die Cast Locknut
IT: with insulated throat.

**CI5020 (-IT) /
CI5032 (-IT)**



Zinc Die Cast Locknut
IT: with insulated throat.

Cat. No.		Trade Size (in.)
Regular	Insulated	
EMT Set-Screw Fittings (Zinc Alloy)		
CI5004	CI5004-IT	1/2
CI5006	CI5006-IT	3/4
CI5008	CI5008-IT	1
CI5010	CI5010-IT	1-1/4
CI5012	CI5012-IT	1-1/2
CI5016	CI5016-IT	2
CI5020	CI5020-IT	2-1/2
CI5024	CI5024-IT	3
CI5032	CI5032-IT	4

Concrete-tight

CI5054 / CI5058



Zinc Die Cast Locknut

Cat. No.	Trade Size (in.)	Offset (in.)
EMT Set-Screw Offset Body Fittings (Zinc Alloy)		
CI5054	1/2	3/8
CI5056	3/4	3/4
CI5058	1	3/4

Concrete-tight

EMT

Set-Screw Couplings



CI5504 / CI5508



CI5120 / CI5132



CI5104 / CI5116



CI5510 / CI5532



Cat. No.		Trade Size (in.)
(Steel)	(Zinc Alloy)	
EMT Set-Screw Couplings		
CI5504	CI5104	1/2
CI5506	CI5106	3/4
CI5508	CI5108	1
CI5510	CI5110	1-1/4
CI5512	CI5112	1-1/2
CI5516	CI5116	2
CI5520	CI5120	2-1/2
CI5524	CI5124	3
-	-	3-1/2
CI5532	CI5132	4

Concrete-tight

CI5164 / CI5168



Cat. No.	Trade Size (in.)	
	EMT	Rigid
EMT / Rigid Couplings (Zinc Alloy)		
CI5164	1/2	1/2
CI5166	3/4	3/4
CI5168	1	1

Concrete-tight

CI5153



CI5154



Cat. No.	Trade Size (in.)		Clamping Range (in.)	
	EMT	Flex.	Min.	Max.
EMT / Flex Couplings (Zinc Alloy)				
CI5153	1/2	3/8	0.17	0.63
CI5154	1/2	1/2	0.75	0.95

EMT

Compression Fittings and Couplings

- All EMT compression connectors and couplings are concrete-tight
- Models from 2-1/2 to 4 in. are also suitable for rigid and IMC conduit



**CI5604 (-IT) /
CI5632 (-IT)**



Steel Locknut
IT: with insulated throat

**CI5804 (-IT) /
CI5832 (-IT)**



Zinc Die Cast Locknut
IT: with insulated throat

Cat. No.				Trade Size (in.)
Regular	Insulated	Regular	Insulated	
(Zinc Alloy)		(Steel)		
EMT Compression Fittings				
CI5804	CI5804-IT	CI5604	CI5604-IT	1/2
CI5806	CI5806-IT	CI5606	CI5606-IT	3/4
CI5808	CI5808-IT	CI5608	CI5608-IT	1
CI5810	CI5810-IT	CI5610	CI5610-IT	1-1/4
CI5812	CI5812-IT	CI5612	CI5612-IT	1-1/2
CI5816	CI5816-IT	CI5616	CI5616-IT	2
CI5820	CI5820-IT	CI5620	CI5620-IT	2-1/2
CI5824	CI5824-IT	CI5624	CI5624-IT	3
CI5832	CI5832-IT	CI5632	CI5632-IT	4



CI5904 / CI5932



CI5704 / CI5732



Cat. No.		Trade Size (in.)
(Zinc Alloy)	(Steel)	
EMT Compression Couplings		
CI5904	CI5704	1/2
CI5906	CI5706	3/4
CI5908	CI5708	1
CI5910	CI5710	1-1/4
CI5912	CI5712	1-1/2
CI5916	CI5716	2
CI5920	CI5720	2-1/2
CI5924	CI5724	3
CI5932	CI5732	4



CI7538



Cat. No.	Max. Flex. Conduit Dia. (in.)	Hole Size (in.)
One Hole Double Sided Strap (Galvanized Steel)		
CI7538* *	1.05	3/16

*Any combination of 3/8 in., 1/2 in. and 3/4 in. EMT, rigid conduit, flexible conduit or teck cables

EMT

Accessories

CI1304 / CI1316



CI1404 / CI1416




CI1520 / CI1532



Cat. No.	Trade Size (in.)	Max. EMT Dia. (in.)	Hole Size (in.)
One Hole EMT Straps (Galvanized Steel)			
CI1304	1/2	0.71	1/4
CI1306	3/4	0.92	1/4
CI1308	1	1.16	5/16
CI1310	1-1/4	1.51	7/16
CI1312	1-1/2	1.74	7/16
CI1316	2	2.20	9/16
Two Hole EMT Straps (Galvanized Steel)			
CI1404	1/2	0.71	3/16
CI1406	3/4	0.92	3/16
CI1408	1	1.16	3/16
CI1410	1-1/4	1.51	1/4
CI1412	1-1/2	1.74	1/4
CI1416	2	2.20	3/8
CI1520	2-1/2	2.88	3/8
CI1524	3	3.50	3/8
CI1528	3-1/2	4.00	1/2
CI1532	4	4.50	1/2

500-SC / 503-SC

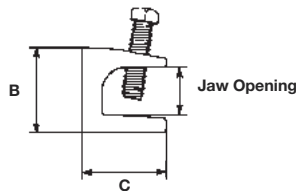

Cat. No.	Trade Size (in.)	Jaw Opening (in.)	Tap Base and Back	Dimensions (in.)		
				A	B	C
Beam Clamps (Malleable Iron)						
500-SC	1/4NC	15/16	1/4-20	1	1-1/4	1-7/16
501	5/16NC	7/8	5/16-18	1-9/16	1-9/16	1-11/16
502	3/8NC	1	3/8-16	2	1-7/8	1-3/4
503-SC	1/2NC	1	1/2-13	2-1/2	2-3/8	2-3/8

CICH-0404 / CICH-3232



Cat. No.	Trade Size (in.)	
	EMT	Rigid
Conduit Hangers-Steel (with nuts & bolts)		
CICH-0404	1/2	1/2
CICH-0606	3/4	3/4
CICH-0808	1	1
CICH-0010	1-1/4	—
CICH-1012	1-1/2	1-1/4
CICH-1200	—	1-1/2
CICH-1616	2	2
CICH-2020	2-1/2	2-1/2
CICH-2424	3	3
CICH-2828	3-1/2	3-1/2
CICH-3232 *	4	4

* Not CSA certified

Cat. No.	Trade Size (in.)	
	EMT	Rigid
Conduit Hangers-Steel (without nuts & bolts)		
6H0	1/2	3/8&1/2
6H1	3/4	3/4
6H2	1	1
6H2-1/2	1-1/4	—
6H3-SC	1-1/2	1-1/4
6H4	—	1-1/2
6H5	2	2
6H6	2-1/2	2-1/2
6H7	3	3
6H8	3-1/2	3-1/2
6H9 *	4	4

* Not CSA certified

EMT

Pull Elbows and Conduit Fittings



CI5204 / CI5206



Zinc Die Cast Locknut

 
CI5304 / CI5306
CI5308-G / CI5310-G




CICA-1/2 / CICA-2



-G: with gasket



CILBA-1/2 / CILBA-2
CILBSA-2-1/2 /
CILBSA-4

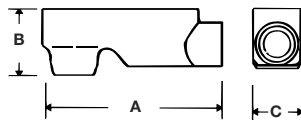

Cat. No.	Trade Size (in.)	Dimensions (in.)		
		A	B	C
Pull Elbows, EMT to Box (Zinc Alloy)				
CI5204	1/2	1-5/16	1-1/8	—
CI5206	3/4	1-1/2	1-1/4	—
Pull Elbows, EMT to EMT (Zinc Alloy)				
CI5304	1/2	1-5/16	15/16	—
CI5306	3/4	1-5/8	1-1/4	—
CI5308-G	1	1-15/16	1-5/8	—
CI5310-G	1-1/4	2-1/4	2	—
EMT Conduit Fittings - "C" Type (Cast Aluminum)				
CICA-1/2	1/2	4-7/8	1-3/8	1-3/8
CICA-3/4	3/4	5-9/16	1-1/2	1-7/16
CICA-1	1	6-1/2	1-3/4	1-3/4
CICA-1-1/4	1-1/4	8-5/8	1-15/16	2-1/2
CICA-1-1/2	1-1/2	8-5/8	2-11/16	2-1/2
CICA-2	2	10-15/16	3	3-3/16
EMT Conduit Fittings - "LB" Type (Cast Aluminum)				
CILBA-1/2	1/2	4-5/16	1-1/2	1-3/8
CILBA-3/4	3/4	4-15/16	1-7/8	1-9/16
CILBA-1	1	6-1/16	2-1/16	1-13/16
CILBA-1-1/4	1-1/4	7-7/8	2-15/16	2-1/2
CILBA-1-1/2	1-1/2	7-7/8	3-1/16	2-1/2
CILBA-2	2	10	3-3/4	3-3/16
CILBSA-2-1/2	2-1/2	13	7-3/8	4-1/4
CILBSA-3	3	13	7-3/8	4-1/4
CILBSA-3-1/2	3-1/2	15-1/4	9	5-1/4
CILBSA-4	4	15-1/4	9	5-1/4

Covers and gaskets are included with all aluminum conduit fittings
Types CICA and CILBA are also suitable for use with rigid conduit

EMT

Conduit Fittings, Accessories and Entrance Heads



CILRL-1/2 / CILRL-2

CITA-1/2 / CITA-2



Combined LL/LR
Left and right
application



Cat. No.	Trade Size (in.)	Dimensions (in.)		
		A	B	C
EMT Conduit Fittings - "LRL" Type (Cast Aluminum)				
CILRL-1/2	1/2	4-7/16	1-11/16	2-1/8
CILRL-3/4	3/4	5-3/16	1-7/8	2-1/4
CILRL-1	1	6	2-3/16	2-1/2
CILRL-1-1/4	1-1/4	7-15/16	2-3/4	3-1/2
CILRL-1-1/2	1-1/2	7-15/16	3-1/4	3-1/2
CILRL-2	2	10-3/16	3-11/16	4-1/8
EMT Conduit Fittings - "T" Type (Cast Aluminum)				
CITA-1/2	1/2	4-7/8	1-3/8	2-1/16
CITA-3/4	3/4	5-9/16	1-3/4	2-1/8
CITA-1	1	6-1/2	2	2-1/2
CITA-1-1/4	1-1/4	8-11/16	2-5/8	3-1/2
CITA-1-1/2	1-1/2	8-11/16	3	3-9/16
CITA-2	2	10-7/8	3-1/4	4-3/16

Covers and gaskets are included with all aluminum conduit fittings
Types CILRL and CITA are also suitable for use with rigid conduit

CIBC-1/2 / CIBC-2



Cat. No.	Trade Size (in.)
Blank Covers for Aluminum Conduit Fittings (Stamped Aluminum)	
CIBC-1/2	1/2
CIBC-3/4	3/4
CIBC-1	1
CIBC-1-1/4	1-1/4
CIBC-2	2

For 1-1/2, use CIBC-1-1/4

CIG-1/2 / CIG-2



Cat. No.	Trade Size (in.)
Gaskets for Aluminum Conduit Fittings (Neoprene)	
CIG-1/2	1/2
CIG-3/4	3/4
CIG-1	1
CIG-1-1/4	1-1/4
CIG-2	2

For 1-1/2, use CIG-1-1/4

CIEFSA-1/2 / CIEFSA-4



Cat. No.	Trade Size (in.)
Service Entrance Heads (Cast Aluminum)	
CIEFSA-1/2	1/2
CIEFSA-3/4	3/4
CIEFSA-1	1
CIEFSA-1-1/4	1-1/4
CIEFSA-1-1/2	1-1/2
CIEFSA-2	2
CIEFSA-2-1/2	2-1/2
CIEFSA-3	3
CIEFSA-3-1/2	3-1/2
CIEFSA-4	4

Consult page D10 for technical specifications