

100% AIRTIGHT


NO ADDITIONAL VAPOUR BARRIER REQUIRED

IMPROVES SOUNDPROOFING

Ceiling Box

F-WOCT

- 26 cubic inch capacity
- Positioning flange eliminate the need to measure for 1/2" drywall
- Flange and 4 hinged cable entry tabs are covered with 100% airtight foam gasket
- Easy access to bottom-mounted ground screw
- Internal screw bosses for all devices
- Dimensions: Box: 3.75" (H) x 3.8" (W) x 2.75" (D)
Flange Diameter: 5.25"

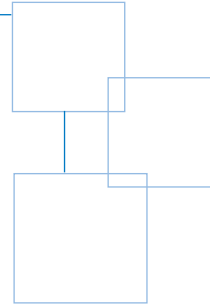


NOTE: CEC rule 30-302: 4) Where the weight of a luminaire does not exceed 23 kg (50 lb), the luminaire shall be permitted to be supported by a ceiling outlet box attached directly to the building structure or by a ceiling outlet box attached to a bar hanger.

Single Gang Switch Box • Armored Cable/BX

FWSWBX

 - 20 cubic inch capacity
- Positioning flange eliminates the need to measure for 1/2" drywall
- Approved for armored (eg. AC90/BX) and nonmetallic sheathed cable flange and external cable/BX connectors are covered with 100% airtight foam gasket
- Easy access to bottom-mounted ground screw
- Internal screw bosses for all devices
- Dimensions: Box: 3.75" (H) x 2.25" (W) x 2.75" (D)
Flange: 5" (H) x 4.25" (W)



Range & Dryer Box • 4-11/16"

F-WRD

- 65 cubic inch capacity
- Positioning flange eliminates the need to measure for 1/2" drywall
- Flange and 4 hinged cable entry tabs (approved for nonmetallic cable up to 8/3) are covered with 100% airtight foam gasket
- Easy access to bottom-mounted ground screw
- Internal screw bosses for all devices
- Dimensions: Box: 4-11/16" (H) x 4-11/16" (W) x 3" (D)
Flange: 6.9" (H) x 6.9" (W)

