


# Ocal®

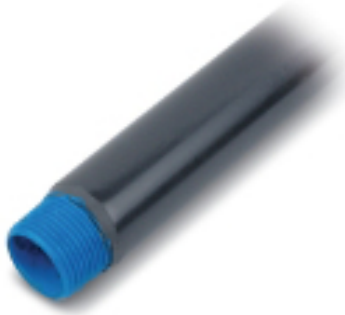

**T&B Catalog Number:** COND3/4-G  
**UPC Number:** 70450826102  
**Description:** 3/4" Dark Gray 40 mil PVC Coated Hot-Dip Galvanized Rigid Steel Conduit.

**Status:** Active

### WEB\_USE

-T&B Product Line -- 087

### Features

- -- A minimum .040" (40 mil) PVC coating on the exterior.
- -- A nominal .002" (2 mil) blue urethane on the interior.
- -- Color coded thread protectors on each end.
- -- Blue urethane coating over Hot-Dip Galvanized threads.

### General

- Material -- Steel
- Finish -- Hot-Dip Galvanized
- Color -- Dark Gray
- Thread Protector Color -- Red

### Dimension Information

- Pipe Size (inches) -- 3/4
- Pipe Size (Metric Size Designator\*) -- 21
- O.D. Steel Only (inches) -- 1.050
- O.D. Steel Only (mm) -- 26.7
- O.D. with PVC (inches) -- 1.130
- O.D. with PVC (mm) -- 28.7
- Nominal Wall Thickness-Steel Only (inches) -- 0.107
- Nominal Wall Thickness-Steel Only (mm) -- 2.71
- Nominal Wall Thickness with PVC (inches) -- .147
- Nominal Wall Thickness with PVC (mm) -- 3.73
- Nominal Inside Diameter (inches) -- 0.836
- Nominal Inside Diameter (mm) -- 21.2
- Cross Section Area (square inches) -- 0.533
- Cross Section Area (mm) -- 13.53
- Length without Couplings -- 9' 11-1/4"
- Length without Couplings (mm) -- 3.03
- Minimum Weight Per Foot (lbs) -- 1.05
- Minimum Weight Per Foot (kil) -- 47.63

### Technical Information

- Chemical Resistance Chart Available on Website

### Packaging

- T&B Order Multiple -- 10
- T&B Inner Pack -- 10
- Package in Units -- 900



-T&B Sold in UOM -- Feet  
-T&B Weight Per UOM -- 1.24 lbs. Each

### Application Support

-T&B Sales Drawings wsd-000042  
-Recommended Installation Procedures Available on Website  
-NEMA Standards-RN 1 Available on Website  
-NEC 310-16 - Conductors for General Wiring Available on Website  
-NEC Table 8 Available on Website

### Notes

-\*Note -- Metric size designator (ANSI C80. 1-1994)  
-\*\*Note -- Coupling(s) shipped with conduit are packaged separately

### Certifications

-RoHS Compliance -- No

### Certifications



File Nbr:  
E 46453

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email:techsupport@tnb.com