



Dual-Rated
T&B Catalog Number:

ASL75-42

UPC Number:

78378613320

Status:

Active

Description:

Type ASL-ALCUL Four-Conductor, Two-Hole Mount for Conductor Range Max 750 kcmil, Min 3/0 Str.

Features

Easy Installation - no special tools required.

General

Style	ALCUL Four-Conductor, Two-Hole Mount
Material	Aluminum
Plating	Tin-Plated
Conductor Range (AL or CU) Maximum	750 kcmil
Conductor Range (AL or CU) Minimum	3/0 Str.

Dimension Information

Length (inches)	4 29/32
Width (inches)	2 5/8
Height (inches)	3
D (inches)	3/8
F (inches)	3/4
I (inches)	1 5/16

Packaging


T&B Order Multiple	3
T&B Inner Pack	3
Package in Units	18
T&B Sold in UOM	Each
T&B Weight Per UOM	80 lbs. per 100

Application Support

T&B Sales Drawings	wsd-000463
--------------------	------------

Certifications

RoHS Compliance	No
-----------------	----

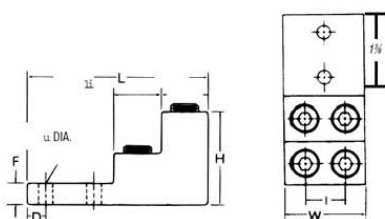

For further technical assistance, please contact us...

Thomas & Betts - USA
 8155 T&B Blvd.
 Memphis, TN 38125
 www.tnb.com

T&B Technical Support
 MS 3B-50
 8155 T&B Blvd.
 Memphis, TN 38125

Hours: 7AM - 6PM CDT
 Monday-Friday
 Phone: (888) 862-3289
 Fax: (901) 252-1321
 Email: techsupport@tnb.com