



## H-Tap Connectors T&B Catalog Number:

**UPC Number:**

WR379

**Status:**

78378610009

**Description:**

Active

Aluminum Wide Range H-Type Compression Connector Main: 4/0 - 3/0 ACSR, 4/0 Str. Tap: 2-6 ACSR, 1-6 Str., 1/0-6 Sol. Die: D, D3

### Features

Made of 1350 Aluminum alloy to provide high strength and conductivity. Prefilled with oxide inhibitor held captive in the rib/connection area.

Enables excellent connector contact without distorting the conductor's shape.

Fold-in tabs provide positive tab interlock as tool closes.

RUS accepted and complies with ANSI C119.4

### General

Style	Type WR - Supplemental O and D Die Connectors
Material	Aluminum
Standard Conductor Main - ACSR	4/0, 3/0
Standard Conductor Main - Stranded	4/0
Standard Conductor Tap - ACSR	2, 4, 6
Standard Conductor Tap - Stranded	1, 2, 3, 4, 6
Standard Conductor Tap - Solid	1/0, 1, 2, 4, 6
Compact Conductor Main - ACSR	266 18/1, 250, 4/0
Compact Conductor Main - Stranded	266, 250, 4/0
Compact Conductor Tap - ACSR	1, 2, 4, 6
Compact Conductor Tap - Stranded	1, 2, 3, 4, 6

### Dimension Information

Length (inches)	1 13/16"
Conductor Diameter Main Max.	0.563
Conductor Diameter Main Min.	0.475
Conductor Diameter Tap Max.	0.332
Conductor Diameter Tap Min.	0.162

### Tooling


Application Tools	JB12A, JB12B, 12A, Y-35
Connector Die	D
No. Indents Mechanical Tool	5
No. Indents Hydraulic Tool	2

### Packaging

T&B Inner Pack	25
Package in Units	250
T&B Sold in UOM	Each
T&B Weight Per UOM	12.56 lbs. per 100

### Certifications

RoHS Compliance	Yes
-----------------	-----

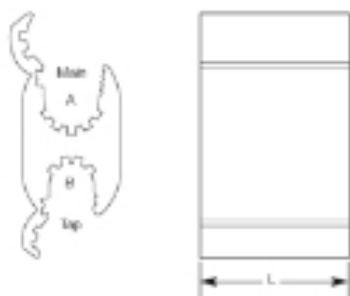

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
8155 T&B Blvd.

T&B Technical Support  
MS 3B-50

Hours: 7AM - 6PM CDT  
Monday-Friday

Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

8155 T&B Blvd.  
Memphis, TN 38125

Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)