


ETQ4024SE10

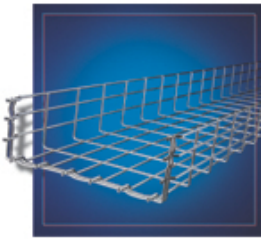

4 in. Deep U-Profile - Straight section



General

Type:	Straight Sections
Application:	Long, straight runs requiring connection of many tray lengths
T&B UPC:	62649098990
T&B Status:	M
Material:	Electro-galvanized

Dimension Information

Wire Size:	0.189 in. / 4.8 mm
Weight lb/ft:	2.41
Weight kg/m:	3.59
Span 5 ft/1.5m lb/ft:	88
Span 5 ft/1.5m kg/m:	40
Span 6 ft/1.75m lb/ft:	61
Span 6 ft/1.75m kg/m:	28
Span 7 ft/2m lb/ft:	45
Span 7 ft/2m kg/m:	20
Span 8 ft/2.5m lb/ft:	34
Span 8 ft/2.5m kg/m:	16
Span 9 ft/2.75m lb/ft:	27
Span 9 ft/2.75m kg/m:	12
Span 10 ft/3m lb/ft:	22
Span 10 ft/3m kg/m:	10
Temperature Range:	-45°C (-49°F) to 150°C (302°F)
Width:	24 in. / 600 mm