



# CADDY® CAT HP J-Hook Clip to Hammer-On Flange Clip, Swivel – CATHP58

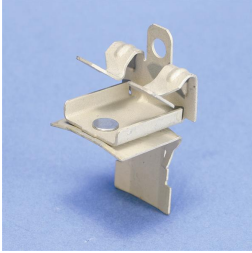

- Requires only a hammer to install
- Rotates 360 degrees to support various directional runs of cable
- Requires no screws, rivets or special tools for assembly
- J-Hooks feature bendable locking tabs that lock on to CADDY® CAT HP components to provide rigidity and stability
- Link to J-Hooks in one of multiple color options to aid in pathway identification and organization
- Customized J-Hook trees can be easily assembled with various J-Hook sizes, colors and configurations
- CADDY® CAT HP components easily attach to any size CADDY CAT HP J-Hook

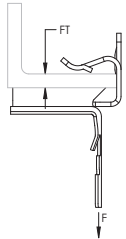

Part Number	CATHP58
Material	Spring Steel
Finish	CADDY® ARMOUR
Flange Thickness (FT)	5/16" – 1/2"
Static Load (F)	75 lb
Certifications	cULus
Standard Packaging Quantity	25 pc
UPC	78285661770
EAN-13	8711893048919

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

#### WARNING

ERICO products shall be installed and used only as indicated in ERICO's product instruction sheets and training materials. Instruction sheets are available at [www.erico.com](http://www.erico.com) and from your ERICO customer service representative. Improper installation, misuse, misapplication or other failure to completely follow ERICO's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death.

Copyright © 2015 ERICO International Corporation. All rights reserved.

CADDY, CADWELD, CRITEC, ERICO, ERIFLEX, ERITECH, and LENTON are registered trademarks of ERICO International Corporation.

