



Pin Terminals
T&B Catalog Number:

RA47PT
 78621003418
 Active

UPC Number:
Status:
Description:


Insulated Vinyl Pin Terminals For Wire Range 22-18 Length .85 Diameter .075

WEB_USE

US Cutsheet PDF Catalog Link <http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

Provides an easy and effective way to terminate stranded wire into European/metric-style terminal blocks.

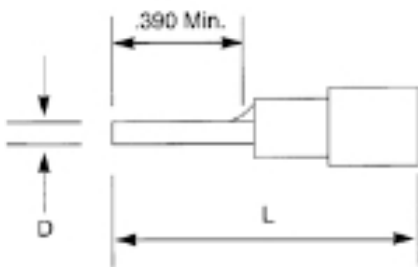

General

Insulation Type	Insulated Vinyl
Terminal Series	RA
Material	Copper
Finish	Electro -Tin Plated
Color	Red
Wire Range	22-18

Dimension Information

Length (inches)	.85
Diameter D (inches)	0.075
Stock Thickness	.03

Specifications

Temperature Rating	105°C
Voltage Rating	300V
Flammability Rating	UL 94 V-0

Tooling

Tool Charts	Available on Website
Application Tools	WT1455, ERG4001, ERG4003
Recommended Tool	ERG4001

Packaging

T&B Order Multiple	1000
T&B Inner Pack	1000
Package in Units	10000
Package Type	Bulk
T&B Sold in UOM	Each
T&B Weight Per UOM	0.18 lbs. per 100
Alternate Package Qty	18RA-47PT

Application Support

Overview	Available on Website
Wire Guide Tables	Available on Website

Notes

Most terminals can be put on Mylar Tape for reel fed applications by adding the suffix M to the bulk

catalog numbers. (I.e. 12050 tool and application dies).

Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com