

Cable Ties



TY523M
Tie body width 0.091 in.



TY524
Tie body width 0.140 in.



TY525M
Tie body width 0.184 in.



TY5272M
Actual size body width 0.270 in.



Std. Cat. No.	Bulk Cat. No.	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Military Standard Part No.	Tensile Strength (lb./N)	Std. Pkg.	Bulk Pkg.
Ty-Rap® Standard Nylon 6/6 Cable Ties								
TY523M	TY23M	0.09/2.29	3.62/91.95	0.63/16.00	MS3367-4	18/80.07	100	1,000
TY52315M	TYB2315M		7.00/177.80	1.50/38.10	—			
TY5232M	TY232M		8.00/203.20	2.00/50.80	—			
TY5234M	TY234M		14.00/355.60	4.00/101.60	—			
TY524M	TY24M	0.14/3.56	5.50/139.70	1.13/28.70	MS3367-5	40/177.90		
TY5242M	TY242M		8.19/208.03	2.00/50.80	—			
TY526M	TY26M		11.10/281.94	3.00/76.20	—	30/133.40		
TY5244M	TY244M		14.50/368.30	4.00/101.60	—			
TY525M	TY25M	0.19/4.83	7.31/185.67	1.75/44.45	MS3367-1	50/222.40		
TY5253M	TY253M		11.60/294.64	3.00/76.20	MS3367-7			
TY528M	TY28M		14.20/360.68	4.00/101.60	MS3367-2			
TY5272M*	TY272M*	0.27/6.86	8.75/222.25	2.00/50.80	—	120/533.80	50	500
TY527M*	TY27M		13.40/340.36	3.50/88.90	MS3367-3			
TY5275M	TY275M		18.00/457.20	5.00/127.00	—			
TY5277M	TY277M		24.30/617.22	7.00/177.80	—			
TY529M	TY29M		30.00/762.00	9.00/228.60	MS3367-6			
TY53510M**	—	0.32/8.13	35.00/889.00	10.00/254.00	—	175/778.40	—	
TY54513M**	—		45.00/1143.00	13.00/330.20	—			

Cable ties made from natural nylon 6/6 are excellent performers in most applications. Nylon 6/6 is recommended for use in temperatures ranging from 185°F to -40°F (85°C to -40°C).

CSA Certified. Natural 6/6 Nylon Cable Ties are suitable for use in air handling spaces in accordance with rules 12-010 (3), (4) and (5), and 12-020 of the CEC.

* Not CSA Certified.

** cUL_{us}

Cable Ties



TY523MX
Tie body width 0.091 in.



TY524MX
Tie body width 0.140 in.



TY525MX
Tie body width 0.184 in.



TY5272MX
Actual size body width 0.270 in.

The MX Series cable ties are recommended for outdoor use.



ULTRAVIOLET
RESISTANT



Std. Cat. No.	Bulk Cat. No.	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Military Standard Part No.	Tensile Strength (lb./N)	Std. Pkg.	Bulk Pkg.
Ty-Rap® Nylon 6/6 – Weather-Resistant								
TY523MX	TY23MX	0.09/2.29	3.62/91.95	0.63/16.00	MS3367-4	18/80.07	100	1,000
TY52315MX	TYB2315MX		7.00/177.80	1.50/38.10	–			
TY5232MX	TY232MX		8.00/203.20	2.00/50.80	–			
TY5234MX	TY234MX		14.00/355.60	4.00/101.60	–			
TY524MX	TY24MX	0.14/3.56	5.50/139.70	1.13/28.70	MS3367-5	40/177.90		
TY5242MX	TY242MX		8.19/208.03	2.00/50.80	–			
TY526MX	TY26MX		11.10/281.94	3.00/76.20	–			
TY5244MX	TY244MX		14.50/368.30	4.00/101.60	–			
TY525MX	TY25MX	0.19/4.83	7.31/185.67	1.75/44.45	MS3367-1	50/222.40		
TY5253MX	TY253MX		11.60/294.64	3.00/76.20	MS3367-7			
TY528MX	TY28MX		14.20/360.68	4.00/101.60	MS3367-2			
TY5272MX[†]	TY272MX[†]	0.27/6.86	8.75/222.25	2.00/50.80	–	120/533.80	50	500
TY527MX[†]	TY27MX		13.40/340.36	3.50/88.90	MS3367-3			
TY5275MX	TY275MX		18.00/457.20	5.00/127.00	–			
TY5277MX	TY277MX		24.30/617.22	7.00/177.80	–			
TY529MX	TY29MX[*]		30.00/762.00	9.00/228.60	MS3367-6			
TY53510MX^{**}	–	0.32/8.13	35.00/889.00	10.00/254.00	–	175/778.40	–	
TY54513MX^{**}	–		45.00/1143.00	13.00/330.20	–			

* For military compliance of weather-resistant black 120 lb. ties, replace suffix X with O (i.e. TY27M-O).

[†] Not Listed or Recognized Models or CSA Certified.

**

CSA Certified. Natural 6/6 Nylon Cable Ties are suitable for use in air handling spaces in accordance with rules 12-010 (3), (4) and (5), and 12-020 of the CEC.

Cable Ties



Std. Pkg. Cat. No.	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Tensile Strength (lb./N)	Std. Pkg.
Ty-Rap® Nylon 6/6 Cable Tie – Colour Assortment					
TY525M-CLRS	0.19/4.83	7.31/185.67	1.75/44.45	50/222.40	10

Cable ties are same size as TY525M shown above. 10 ties in each colour (black, brown, red, orange, yellow, green, blue, purple, grey & white) are packaged. 100 total cable ties per package.

The colours you need in convenient packs!

Ty-Rap® Nylon 6.6 Cable Ties – Colour Assortment

- Construction – nylon 6.6, 316 stainless steel locking device



Std. Cat. No.	Bulk Cat. No.	Description	Length (in./mm)	Tensile Strength (lb./N)	Bulk Pkg.
-	TY525M-CLRS	Multi-Coloured Natural Nylon (10 each of standard ten colours)	7.31/185.67	50/222.40	100 ties
-	TY25M-0	Black, Natural Nylon			1,000 Ties
-	TY25M-1	Brown, Natural Nylon			
-	TY25M-2	Red, Natural Nylon			
-	TY25M-3	Orange, Natural Nylon			
-	TY25M-4	Yellow, Natural Nylon			
-	TY25M-5	Green, Natural Nylon			
-	TY25M-6	Blue, Natural Nylon			
-	TY25M-7	Purple, Natural Nylon			
-	TY25M-8	Grey, Natural Nylon			
-	TY25M-9	White, Natural Nylon			

 
For use in temperatures ranging from -40°F to 185°F (-40°C to 85°C)

- UL Listed Natural 6.6 Nylon Cable Ties are suitable for use in air handling spaces (plenums) in accordance with Section 300.22 (C) & (D) of the National Electrical Code
- 100 standard ties in black, brown, red, orange, yellow, green, blue, purple, grey and white (10 each)
- Recommended tooling – ERG-50, WT1-TB


Natural nylon is standard. For coloured Ty-Rap® ties, add the following suffix numbers to catalogue numbers. **Example:** TY25M-2 would be red TY25M. (Consult Regional Sales Office for ordering information.)

How to Order Coloured Ty-Rap® Cable Ties and Accessories


Colour	Suffix No.	Colour	Suffix No.	Colour	Suffix No.	Colour	Suffix No.
Black	X	Red	2	Green	5	Grey	8
(outdoor)		Orange	3	Blue	6	White	9
Brown	1	Yellow	4	Purple	7		



TY533M

 

TY534M

 

TY535M
TY5354M




TY537M


Great for use with screws, nuts and bolts for secure fastening to surfaces.

Std. Cat. No.	Bulk Cat. No.	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Mounting Hole	Tensile Strength (lb./N)	Std. Pkg.	Bulk Pkg.
Ty-Rap® Mounting Head Cable Ties								
TY533M	TY33M	0.09/2.29	4.00/101.60	0.63/16.00	#4	18/80.07	100	1,000
TY534M	TY34M	0.14/3.56	6.00/152.40	1.13/28.70	#8	40/177.90		
TY535M	TY35M	0.18/4.57	7.80/198.12	1.75/44.45	#10	50/222.40		
TY5354M	TY354M		14.60/370.84	4.00/101.60	#10			
TY1435M	-	0.19/4.83	7.80/198.12	1.77/44.96	0.248		-	
TY635M	-		7.24/183.90		0.138		100	
TYF535M	TYF35M				0.138			
TY537M	TY37M	0.30/7.62	13.90/353.06	3.50/88.90	1/4	120/533.80	50	500

 Cable ties made from natural nylon 6/6 are excellent performers in most applications. Nylon 6/6 is recommended for use in temperatures ranging from 185°F to -40°F (85°C to -40°C).



TY554M

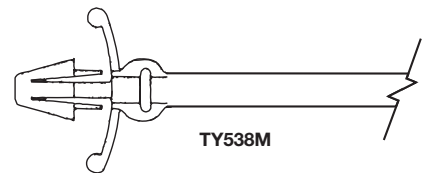

TY538M

For use in 3/16 in. and 1/4 in. pre-drilled holes. Thickness panel 0.094 max. (TY554M) Range 0.04 - 0.156 (TY538M)


Std. Cat. No.	Bulk Cat. No.	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Mounting Hole	Tensile Strength (lb./N)	Std. Pkg.	Bulk Pkg.
Ty-Rap® Push Mount Cable Ties								
TY554M	TY54M	0.14/3.56	5.96/151.38	1.13/28.70	3/16	40/177.90	100	1,000
TY538M	TY38M*	0.18/4.57	7.80/198.12	1.75/44.45	1/4	50/222.40		

Cable ties made from natural nylon 6/6 are excellent performers in most applications. Nylon 6/6 is recommended for use in temperatures ranging from 185°F to -40°F (85°C to -40°C).


* Nylon 6/6 UV weather-resistant version available (TY38MX).



 
TY533MX



TY534MX

 

TY535MX
TY5354MX

 

TY537MX

The MX series cable ties are recommended for outdoor use.

Std. Cat. No.	Bulk Cat. No.	Body Width (in./mm)	Length (in./mm)	Max. Wire Bundle Dia. (in./mm)	Mounting Hole	Tensile Strength (lb./N)	Std. Pkg.	Bulk Pkg.	
Ty-Rap® Nylon 6/6 Weather-Resistant									
TY533MX	TY33MX	0.09/2.29	4.00/101.60	0.63/16.00	#4	18/80.07	100	1,000	
TY534MX	TY34MX	0.14/3.56	6.00/152.40	1.13/28.70	#8	40/177.90			
TY535MX	TY35MX	0.18/4.57	7.80/198.12	1.75/44.45	#10	50/222.40			
TY5354MX	TY354MX		14.60/370.84	4.00/101.60	#10				
TY537MX	TY37MX	0.30/7.62	13.90/353.06	3.50/88.90	1/4		120/533.80	50	500