


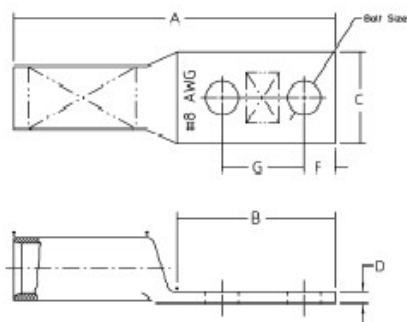

Standard Barrel Copper Lug

T&B Catalog Number:

54228

UPC Number:

78621054228

Status:

Active

Description:

Copper Two-Hole Lug - Straight Standard Barrel - max 35KV, 1000 kcmil Wire, 1/2" Bolt Size, 1 3/4" Hole Spacing, Tin Plated with Inspection Hole, N/A 125

General

Material	Copper
Finish	Tin Plated
Wire Size	1000 kcmil
Number of Studs	2
Stud Size	1/2
Bolt Hole Spacing	1 3/4
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Code	125

Dimension Information

A (inches)	5.453
B (inches)	3
C (inches)	2.266
D (inches)	.297
E (inches)	1.547
F (inches)	.5
G (inches)	1.75

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Order Multiple	3
T&B Inner Pack	3
Package in Units	30
T&B Sold in UOM	Each
T&B Weight Per UOM	1.25 lbs. Each

Application Support

T&B Instruction Sheets	ta00884-tb2
Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com