

**Splice Connector**  
**T&B Catalog Number:**

2RAS18X

**UPC Number:**

78621070326

**Status:**

Active

**Description:**

Heat-Shrinkable Polyolefin Butt Splice Connector For Wire Range 22-18 Length 1.5 Diameter .25, Red




**WEB\_USE**

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

**Features**

Self-insulated with heat-shrinkable polyolefin and internally coated sealant. Upon completed installation, a fully sealed connection is achieved to protect the joint against the degrading effects of galvanic action, corrosion, and environmental exposure.

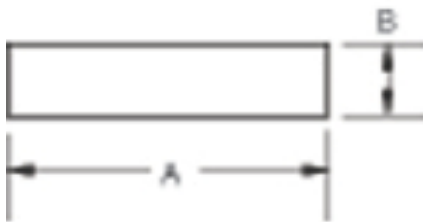

**General**

Insulation Type	Heat-Shrinkable Polyolefin
Terminal Series	RAS
Material	Copper
Finish	Electro -Tin Plated
Color	Red
Wire Range	22-18

**Dimension Information**

Maximum Insulation (inches)	.170
A (inches)	1.50
B (inches)	.25

**Specifications**

Temperature Rating	150°C
Voltage Rating	600V
Flammability Rating	UL 94 V-0

**Tooling**

Tool Charts	Available on Website
Application Tools	WT1255
Recommended Tool	ERG4255

**Packaging**

T&B Order Multiple	50
T&B Inner Pack	50
Package in Units	2500
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	3.75 lbs. per 1000
Alternate Package Qty	RAAS22X

**Application Support**

Overview	Available on Website
Wire Guide Tables	Available on Website

**Certifications**

RoHS Compliance	Yes
-----------------	-----

## Certifications



File Nbr:  
E9809

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)