



## Locking Fork Terminal T&B Catalog Number:

**UPC Number:**  
**Status:**  
**Description:**

RC2207  
78621082042  
Active

Insulated Vinyl Locking Fork Terminal For Wire Range 12-10 Stud Size #6, Yellow


### WEB\_USE

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

### Features

Locking fork terminals have a specially designed tongue that lets them go on like a fork and stay on like a ring.

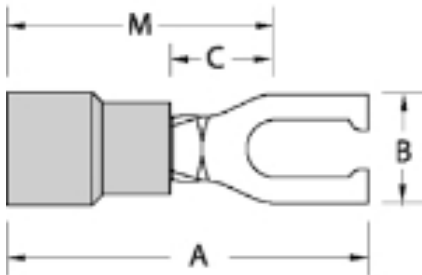

### General

Insulation Type	Insulated Vinyl
Terminal Series	RC
Material	Copper
Finish	Electro -Tin Plated
Color	Yellow
Wire Range	12-10
Stud Size	#6

### Dimension Information

Maximum Insulation (inches)	.220
Stock Thickness	.04
A (inches)	1.09
B (inches)	.31
C (inches)	.27
M (inches)	.90

### Specifications

Temperature Rating	105°C
Voltage Rating	600V
Flammability Rating	UL 94 V-0

### Tooling

Tool Charts	Available on Website
Application Tools	ERG4001, ERG4003, WT145C, WT2000, WT112M, WT145C
Recommended Tool	ERG4001

### Packaging

T&B Order Multiple	500
T&B Inner Pack	500
Package in Units	5000
Package Type	Bulk
T&B Sold in UOM	Each
T&B Weight Per UOM	0.48 lbs. per 100
Alternate Package Qty	10RC-6FL

### Application Support

Overview	Available on Website
Wire Guide Tables	Available on Website

## Notes

Most terminals can be put on Mylar Tape for reel fed applications by adding the suffix M to the bulk catalog numbers.

## Certifications

RoHS Compliance Yes

## Certifications



File Nbr:  
E9809

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email:techsupport@tnb.com