



Long Barrel Copper Lug T&B Catalog Number:

256-30695-1298

UPC Number:

78621031071

Status:

Active

Description:

Copper Two-Hole Lug - Straight Long Standard Barrel - max 35KV, #14-10 Wire, 1/4" Bolt Size, 5/8" Hole Spacing, Tin Plated Blind End, ERG2002 N/A

General

Material	Copper
Finish	Tin Plated
Wire Size	#14-10
Number of Studs	2
Stud Size	1/4
Bolt Hole Spacing	5/8
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	C Nest
Die Code	N/A

Dimension Information

A (inches)	1.89
B (inches)	1.22
C (inches)	.50
D (inches)	.05
E (inches)	.20
F (inches)	.25
G (inches)	0.625

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Inner Pack	50
Package in Units	500
T&B Sold in UOM	Each
T&B Weight Per UOM	1.19 lbs. per 100

Application Support

Product Overview	Available on Website
------------------	----------------------


Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

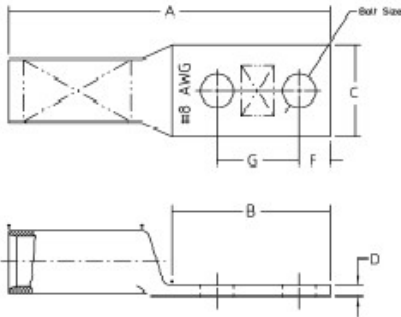

8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com