



## H-Tap Connectors T&B Catalog Number:

WR9  
78378610035  
Active

**UPC Number:**  
**Status:**  
**Description:**

Aluminum Wide Range H-Type Compression Connector Main: 3-6 ACSR, 2-6 Str., 1-4 Sol., Tap: 8-14 Str., 8-14 Sol., Die: 5/8 OR BG

### Features

- Made of 1350 Aluminum alloy to provide high strength and conductivity. Prefilled with oxide inhibitor held captive in the rib/connection area.
- Enables excellent connector contact without distorting the conductor's shape.
- Fold-in tabs provide positive tab interlock as tool closes.
- RUS accepted and complies with ANSI C119.4

### General

Style	Type WR - Wide Range Street Lighting Tap Connectors
Material	Aluminum
Standard Conductor Main - ACSR	3, 4, 6
Standard Conductor Main - Stranded	2, 3, 4, 6
Standard Conductor Main - Solid	1, 2, 3, 4

### Dimension Information

Length (inches)	13/16"
Conductor Diameter Main Max.	0.292
Conductor Diameter Main Min.	0.184

### Tooling

Connector Die	5/8 BG
No. Indents Mechanical Tool	3

### Packaging


T&B Order Multiple	2
T&B Inner Pack	50
Package in Units	500
T&B Sold in UOM	Each
T&B Weight Per UOM	2.94 lbs. per 100

### Notes

- Will accept standard conductors of the same size with a 3 percent reduction of compressed diameter.
- Fig. 2

### Certifications

RoHS Compliance	Yes
-----------------	-----

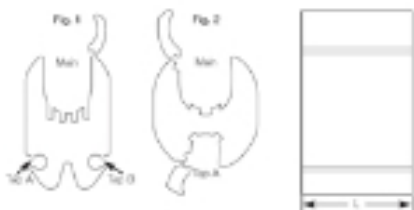

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email:techsupport@tnb.com