

Splice Connector
T&B Catalog Number:

2RCS10X

UPC Number:

78621070328

Status:

Active

Description:

Heat-Shrinkable Polyolefin Butt Splice Connector For Wire Range 12-10 Length 1.6 Diameter .31, Yellow




WEB_USE

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

Self-insulated with heat-shrinkable polyolefin and internally coated sealant. Upon completed installation, a fully sealed connection is achieved to protect the joint against the degrading effects of galvanic action, corrosion, and environmental exposure.

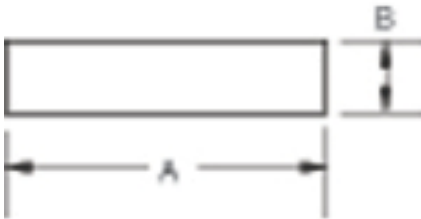

General

Insulation Type	Heat-Shrinkable Polyolefin
Terminal Series	RCS
Material	Copper
Finish	Electro -Tin Plated
Color	Yellow
Wire Range	12-10

Dimension Information

Maximum Insulation (inches)	.250
A (inches)	1.60
B (inches)	.31

Specifications

Temperature Rating	150°C
Voltage Rating	600V
Flammability Rating	UL 94 V-0

Tooling

Tool Charts	Available on Website
Application Tools	WT1255
Recommended Tool	ERG4255

Packaging

T&B Order Multiple	25
T&B Inner Pack	25
Package in Units	125
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	8.75 lbs. per 1000
Alternate Package Qty	RCCS22X

Application Support

Overview	Available on Website
Wire Guide Tables	Available on Website

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com