

Long Barrel Aluminum Lug T&B Catalog Number:

60178

UPC Number:


78621060178

Status:

Active

Description:

Aluminum One-Hole Lug - Straight Long Barrel - max 35KV, 750 kcmil Wire, 5/8" Bolt Size, Tin Plated Blind End, Yellow 115H

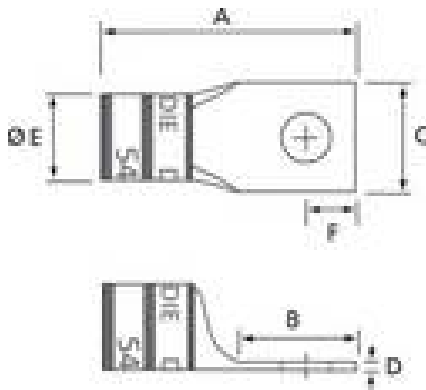

General

Material	Aluminum
Finish	Tin Plated
Wire Size	750 kcmil
Number of Studs	1
Stud Size	5/8
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Yellow
Die Code	115H

Dimension Information

A (inches)	6.03
B (inches)	2
C (inches)	2.13
D (inches)	.4
E (inches)	1.5
F (inches)	.75

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Order Multiple	1
T&B Inner Pack	1
Package in Units	10
T&B Sold in UOM	Each
T&B Weight Per UOM	72.88 lbs. per 100

Application Support

T&B Instruction Sheets	ta00880-tb2
Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com