

Standard Barrel Copper Lug

T&B Catalog Number:

58177

UPC Number:

78621058177

Status:

Active

Description:

Copper One-Hole Lug - Straight Standard Barrel - max 35KV, 400 Flex Wire, 1/2" Bolt Size, Tin Plated with Inspection Hole, N/A 80

General

Material	Copper
Finish	Tin Plated
Wire Size	400 Flex
Number of Studs	1
Stud Size	1/2
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	N/A
Die Code	80

Dimension Information

A (inches)	3.31
B (inches)	1.25
C (inches)	1.61
D (inches)	0.22
E (inches)	1.04
F (inches)	1/2

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

Package in Units	6
T&B Sold in UOM	Each
T&B Weight Per UOM	38.31 lbs. per 100

Application Support


T&B Instruction Sheets	ta00884-tb2
Product Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

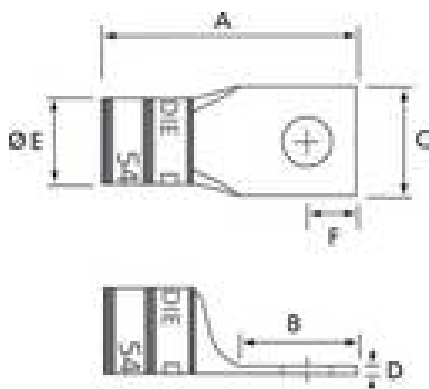

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com