










4 in. Octagonal Boxes

Conduit Knockouts

				
BCOBEX	BC56111	BC54151-K	CI54151-KSSX	
Octagonal box extension.	Ceiling pan.	Concentric knockouts.	Concentric knockouts. "Wraparound" bracket for 2-1/2 in. and 3-5/8 in. steel studs. With integral support bracket.	
				
BC55151-K	BC54171-K	CI54171-KSSX	CI54171-KSSX-1	CI55171-K
Extension ring with ground screw. Concentric knockouts.	Concentric knockouts.	Concentric knockouts. "Wraparound" bracket for 2-1/2 in. and 3-5/8 in. steel studs. With integral support bracket.	Mounting strap (offset for 2 x 1/2 in. drywall thicknesses).	Extension ring with ground screw. Concentric knockouts.


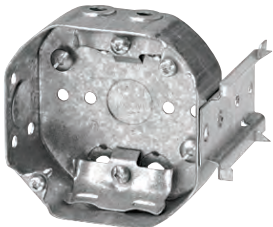
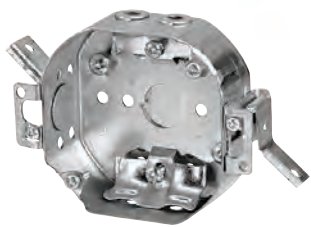

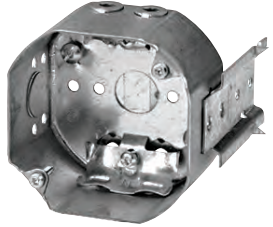



Cat. No.	Description
1/2 in. Deep — Extensions	
BCOBEX	Extension for octagonal boxes. 1/2 in. non-adjustable depth. Complete with mounting screws (5 cu. in.)

Cat. No.	Volume (Cu. in.)	Features		Knockouts			
		Bracket	Raised Ground Screw	1/2 in. sides	1/2 in. bottom	3/4 in. sides	3/4 in. bottom
1-1/2 in. Deep							
BC56111	5.0	-	yes	-	4	-	-
1-1/2 in. Deep							
BC54151-K	15.0	-	yes	4	4	2	2
CI54151-KSSX	15.0	"SSX"	yes	2	4	2	2
BC55151-K	15.0	-	yes	4	-	2	-
2-1/8 in. Deep							
BC54171-K	21.0	-	yes	4	4	2	2
CI54171-KSSX	21.0	"SSX"	yes	2	4	2	2
CI54171-KSSX-1	21.0	"SSX-1"	yes	2	4	2	2
CI55171-K	21.0	-	yes	4	-	2	-

4 in. Octagonal Boxes

Nonmetallic Sheathed Cable Clamps

		
BC54151-L	BC54151-LB	BC54151-LD
Prepositioned depth tabs recessed 1/2 in.	Side bracket, with holding prongs and prepositioned depth tabs.	Swing-arm" rework brackets. Max. wall thickness: 3/4 in.. Max. load capacity: 12 lb. (5.5 kg).
		
BC54171-L	BC54171-LB	CI54171-LF
Side bracket, with holding prongs.	Side bracket, with holding prongs.	Ceiling fan box. (Supplied with 2 #10-32 machine screws and star washers.) Max. load capacity: 35 lb. (15.6 kg).



Cat. No.	Volume (Cu. in.)	Features		Knockouts		Pryouts	
		Bracket	Raised Ground Screw	1/2 in. sides	1/2 in. bottom	sides	bottom
1-1/2 in. Deep							
BC54151-L	15.0	-	yes	2	1	4	4
BC54151-LB	15.0	"B"	yes	1	1	4	4
BC54151-LD	15.0	rework	yes	-	1	4	4
CI54151-LF	15.0	-	yes	2	1	4	4
2-1/8 in. Deep							
BC54171-L	21.0	-	yes	2	1	4	4
BC54171-LB	21.0	"B"	yes	1	1	4	4
BC54171-LD	21.0	rework	-	-	1	4	4
CI54171-LF	21.0	-	yes	2	1	4	4

FOR USE WITH NONMETALLIC SHEATHED CABLE ONLY


Note: NEC 2012 rule 30-302: Subrule (4) requires that a ceiling-mounted luminaire weighing 23 kg or less be supported on a ceiling outlet box attached directly to the building structure. A bar hanger may also be used to attach a ceiling outlet box to the building structure when the luminaire weighs 23 kg or less.

4 in. Octagonal Boxes

Armoured and Nonmetallic Sheathed Cable Clamps



BC54151-LA

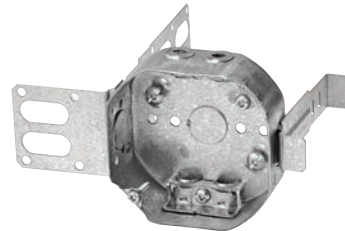


BC54151-LSSAX


"Wraparound" bracket for 2-1/2 in. and 3-5/8 in. steel studs. With integral support bracket.



BC54171-LA

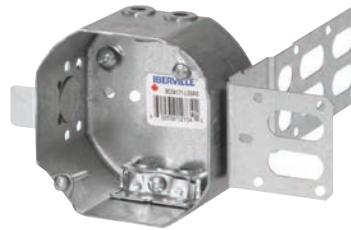

BC54171-LSSAX

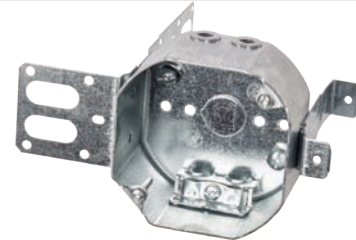

BC54171-LSSAX-5/8



Cat. No.	Volume (Cu. in.)	Features		Knockouts		Pryouts	
		Bracket	Raised Ground Screw	1/2 in. sides	1/2 in. bottom	sides	bottom
1-1/2 in. Deep							
BC54151-LA	15.0	-	yes	2	1	4	-
BC54151-LSSAX	15.0	"SSX"	yes	-	1	4	-
2-1/8 in. Deep							
BC54171-LA	21.0	-	yes	2	1	4	-
BC54171-LSSAX	21.0	"SSX"	yes	-	1	4	-
BC54171-LSSAX-5/8	21.0	"SSX"	yes	-	1	4	-

4 in. Octagonal Boxes

Covers



Cat. No.	Description
4 in. Round Covers	
BC54-C-1	Flat blank
BC54-C-6	Flat with 1/2 in. conduit knockout
CI54-C-64	Flat for 1-13/32 in. diameter, 15 A single receptacle. Device mounting screws included
BC54-C-65	Flat for duplex receptacle. Device mounting screw included
BC54-C-94	Flat for toggle switch. Device mounting screws included
5 in. Round Covers (White Enamel Paint)	
BC54-COV	Flat with 1/2 in. conduit knockout. Mounting screws included
BC54-COV-1	Flat blank. Mounting screws included