



## Long Barrel Copper Lug T&B Catalog Number:

256-30695-1160

**UPC Number:**

78621006891

**Status:**

Active

**Description:**

Copper Two-Hole Lug - Straight Long Barrel - max 35KV, #2 AWG Wire, 3/8" Bolt Size, 1" Hole Spacing, Tin Plated Blind End, Brown 33

### General

Material	Copper
Finish	Tin Plated
Wire Size	#2 AWG
Number of Studs	2
Stud Size	3/8
Bolt Hole Spacing	1
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Brown
Die Code	33

### Dimension Information

A (inches)	3.125
B (inches)	2
C (inches)	.672
D (inches)	.094
E (inches)	.406
F (inches)	.375
G (inches)	1

### Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

### Packaging

T&B Inner Pack	10
Package in Units	50
T&B Sold in UOM	Each
T&B Weight Per UOM	6.19 lbs. per 100

### Application Support

T&B Instruction Sheets	ta01025-tb2
Product Overview	Available on Website


### Notes

Dimensions given for reference only. Dimensions may vary up to .030.

### Certifications

RoHS Compliance	Yes
-----------------	-----

**For further technical assistance, please contact us...**

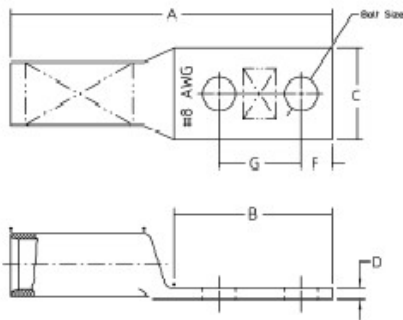

8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)