



Wire Joints
T&B Catalog Number:


54620
 78621054620
 Active

UPC Number:
Status:
Description:

Copper Cable Joint for Wire Range Min: 3 #8 Sol. or Str., Max: 1 #4 w/2 #10 Sol. or Str., Brown Die

Features

- Ideal for pigtailling, tapping multiple conductors or 2-way splicing. Offers lowest installed cost.
- Form a permanent installation in minimal space. Easily insulated.
- Color-coded to dies for positive matching and compression.

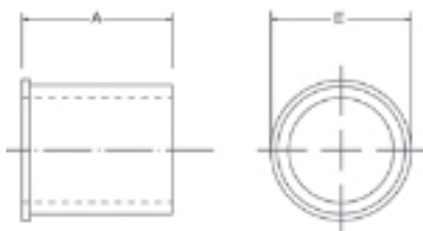

General

Material	Copper
Finish	Tin-Plated
Die Color	Brown
Die Code	33
Connector Range Min.	3 #8 Sol. or Str.
Connector Range Max.	1 #4 w/2 #10 Sol. or Str.
Circular Mil Area Min.	49530
Circular Mil Area Max.	65560

Dimension Information

A (inches)	.417
E (inches)	.475

Specifications

Voltage Rating	600V
----------------	------

Tooling

Application Tools	TBM8, TBM8S, TBM5, TBM5S, TBM6, TBM6S
TBM8/8S Die Catalog Number	13462
TBM5/5S Die Catalog Number	13455
TBM6/6S Die Catalog Number	13474, 13477
Connector & Tooling Chart	Available on Website

Packaging

Package in Units	100
T&B Sold in UOM	Each
T&B Weight Per UOM	1 lbs. per 100

Application Support

Popular Wire Combinations	Available on Website
---------------------------	----------------------

Notes

Hand tools only.

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com