

Long Barrel Copper Lug

T&B Catalog Number:

54917BE

UPC Number:


78621019478

Status:

Active

Description:

Copper One-Hole Lug - Straight Long Barrel - max 35KV, 400 kcmil Wire, 5/8" Bolt Size, Tin Plated Blind End, Blue 76

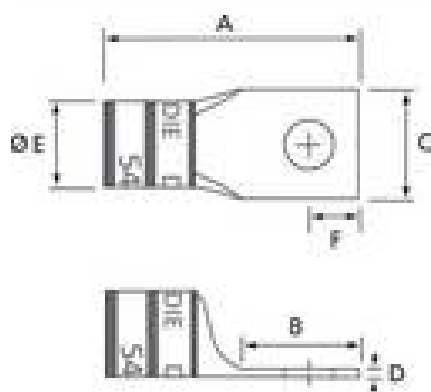

General

Material	Copper
Finish	Tin Plated
Wire Size	400 kcmil
Number of Studs	1
Stud Size	5/8
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Blue
Die Code	76

Dimension Information

A (inches)	4.031
B (inches)	1.563
C (inches)	1.406
D (inches)	.172
E (inches)	.953
F (inches)	.625

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Order Multiple	2
T&B Inner Pack	2
Package in Units	10
T&B Sold in UOM	Each
T&B Weight Per UOM	17 lbs. per 100

Application Support

T&B Instruction Sheets	ta01025-tb2
Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com