


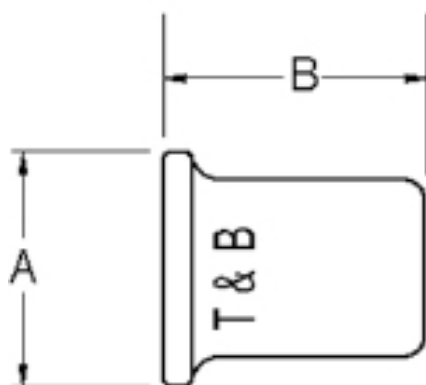

Wire Joints

T&B Catalog Number:

PT80

UPC Number:

78621080383

Status:

Active

Description:

Non-Insulated Wire Joints for Minimum Wire Range 2 (#16) to Maximum Wire Range 4 (#10), Metallic

WEB_USE

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

Standards

UL, CSA

Application

Provides terminating point for a group of wires running in one direction.

General

Insulation Type	Non-Insulated
Terminal Series	PT
Color	Metallic
Wire Range	2 (#16) - 4 (#10)

Dimension Information

A (inches)	.35
B (inches)	.62

Tooling

Tool Charts	Available on Website
Application Tools	WT161M
Recommended Tool	WT161M

Packaging

T&B Order Multiple	100
T&B Inner Pack	100
Package in Units	500
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	0.6 lbs. per 100

Application Support

Overview	Available on Website
Wire Guide Tables	Available on Website

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com