



## Locking Fork Terminal T&B Catalog Number:

**UPC Number:**  
**Status:**  
**Description:**

RA18-10FL  
78621088729  
Active

Insulated Nylon Locking Fork Terminal For Wire Range 22-16 Stud Size #10, Red


### WEB\_USE

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

### Features

Locking fork terminals have a specially designed tongue that lets them go on like a fork and stay on like a ring.

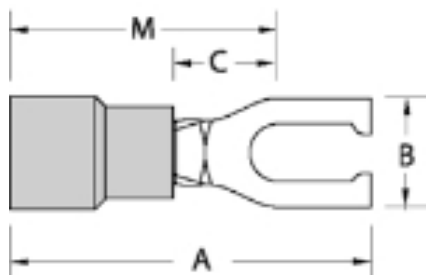

### General

|                 |                     |
|-----------------|---------------------|
| Insulation Type | Insulated Nylon     |
| Terminal Series | RA                  |
| Material        | Copper              |
| Finish          | Electro -Tin Plated |
| Color           | Red                 |
| Wire Range      | 22-16               |
| Stud Size       | #10                 |

### Dimension Information

|                             |      |
|-----------------------------|------|
| Maximum Insulation (inches) | .136 |
| Stock Thickness             | .03  |
| A (inches)                  | .86  |
| B (inches)                  | .29  |
| C (inches)                  | .25  |
| M (inches)                  | .71  |

### Specifications

|                     |           |
|---------------------|-----------|
| Temperature Rating  | 105°C     |
| Voltage Rating      | 600V      |
| Flammability Rating | UL 94 V-2 |

### Tooling

|                   |  |
|-------------------|--|
| Tool Charts       | Available on Website                             |
| Application Tools | ERG4001, ERG4003, WT145C, WT2000, WT112M, WT145A |
| Recommended Tool  | ERG4001  |

### Packaging

|                       |                  |
|-----------------------|------------------|
| T&B Order Multiple    | 100              |
| T&B Inner Pack        | 100              |
| Package in Units      | 500              |
| Package Type          | Standard         |
| T&B Sold in UOM       | Each             |
| T&B Weight Per UOM    | 0.5 lbs. per 100 |
| Alternate Package Qty | RA2253           |

### Application Support

|                   |                      |
|-------------------|----------------------|
| Overview          | Available on Website |
| Wire Guide Tables | Available on Website |

## Certifications

RoHS Compliance Yes

## Certifications



File Nbr:  
E9809

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email:techsupport@tnb.com