


S2 Type

Main Amp. Rating	Factory Assembled No.	Interior	Main Device	Front		Box
			MCB	Surface	Flush	
3 Phase 4 Wire 480Y/277V						
100	S2E18BD100A	I2E18MC250A	MBKBC3	S32B	F32B	B32
	S2E18BD100C	I2E18MC250C	MBKBC3	S32B	F32B	B32
	S2E30BD100A	I2E30MC250A	MBKBC3	S38B	F38B	B38
	S2E30BD100C	I2E30MC250C	MBKBC3	S38B	F38B	B38
	S2E42BD100A	I2E42MC250A	MBKBC3	S44B	F44B	B44
	S2E42BD100C	I2E42MC250C	MBKBC3	S44B	F44B	B44
125	S2E18E4125A	I2E18MC250A	MBKED3	S32B	F32B	B32
	S2E18E4125C	I2E18MC250C	MBKED3	S32B	F32B	B32
	S2E30E4125A	I2E30MC250A	MBKED3	S38B	F38B	B38
	S2E30E4125C	I2E30MC250C	MBKED3	S38B	F38B	B38
	S2E42E4125A	I2E42MC250A	MBKED3	S44B	F44B	B44
	S2E42E4125C	I2E42MC250C	MBKED3	S44B	F44B	B44
250	S2E18FD250A	I2E18MC250A	MBKFD3	S32B	F32B	B32
	S2E18FD250C	I2E18MC250C	MBKFD3	S32B	F32B	B32
	S2E30FD250A	I2E30MC250A	MBKFD3	S38B	F38B	B38
	S2E30FD250C	I2E30MC250C	MBKFD3	S38B	F38B	B38
	S2E42FD250A	I2E42MC250A	MBKFD3	S44B	F44B	B44
	S2E42FD250C	I2E42MC250C	MBKFD3	S44B	F44B	B44
400	S2E42JD400A	I2E42MC400A	SMBKJD3	24S68B	24F68B	SBD68
	S2E42JD400C	I2E42MC400C	SMBKJD3	24S68B	24F68B	SBD68
600	S2E42LD600A	I2E42MC600A	SMBKLD3	24S68B	24F68B	SBD68
	S2E42LD600C	I2E42MC600C	SMBKLD3	24S68B	24F68B	SBD68

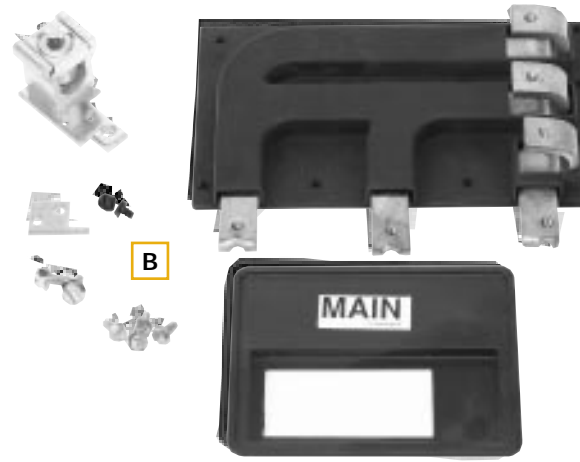

SE Type

Main Amp. Rating	Factory Assembled No.	Interior	Main Device	Front		Box
			MCB	Surface	Flush	
1 Phase 3 Wire 120/240V						
125	SEA30E4125A	IEA30MC250A	SMBKED1	24S44B	24F44B	SBD44
	SEA30E4125C	IEA30MC250C	SMBKED1	24S44B	24F44B	SBD44
	SEA42E4125A	IEA42MC250A	SMBKED1	24S50B	24F50B	SBD50
	SEA42E4125C	IEA42MC250C	SMBKED1	24S50B	24F50B	SBD50
250	SEA30FX250A	IEA30MC250A	SMBKFD1	24S44B	24F44B	SBD44
	SEA30FX250C	IEA30MC250C	SMBKFD1	24S44B	24F44B	SBD44
	SEA42FX250A	IEA42MC250A	SMBKFD1	24S50B	24F50B	SBD50
	SEA42FX250C	IEA42MC250C	SMBKFD1	24S50B	24F50B	SBD50
400	SEA42JD400A	IEA42MC400A	SMBKJD1	24S68B	24F68B	SBD68
	SEA42JD400C	IEA42MC400C	SMBKJD1	24S68B	24F68B	SBD68
600	SEA42LD600A	IEA42MC600A	SMBKLD1	24S68B	24F68B	SBD68
	SEA42LD600C	IEA42MC600C	SMBKLD1	24S68B	24F68B	SBD68
3 Phase 4 Wire 208Y/120V						
125	SEC30E4125A	IEX30MC250A	SMBKED3	24S44B	24F44B	SBD44
	SEC30E4125C	IEX30MC250C	SMBKED3	24S44B	24F44B	SBD44
	SEC42E4125A	IEX42MC250A	SMBKED3	24S50B	24F50B	SBD50
	SEC42E4125C	IEX42MC250C	SMBKED3	24S50B	24F50B	SBD50
250	SEC30FX250A	IEX30MC250A	SMBKFD3	24S44B	24F44B	SBD44
	SEC30FX250C	IEX30MC250C	SMBKFD3	24S44B	24F44B	SBD44
	SEC42FX250A	IEX42MC250A	SMBKFD3	24S50B	24F50B	SBD50
	SEC42FX250C	IEX42MC250C	SMBKFD3	24S50B	24F50B	SBD50
400	SEC42JD400A	IEX42MC400A	SMBKJD3	24S68B	24F68B	SBD68
	SEC42JD400C	IEX42MC400C	SMBKJD3	24S68B	24F68B	SBD68
600	SEC42LD600A	IEX42MC600A	SMBKLD3	24S68B	24F68B	SBD68
	SEC42LD600C	IEX42MC600C	SMBKLD3	24S68B	24F68B	SBD68
3 Phase 4 Wire 480Y/277V						
125	SEE30E4125A	IEE30MC250A	SMBKED3	24S44B	24F44B	SBD44
	SEE30E4125C	IEE30MC250C	SMBKED3	24S44B	24F44B	SBD44
	SEE42E4125A	IEE42MC250A	SMBKED3	24S50B	24F50B	SBD50
	SEE42E4125C	IEE42MC250C	SMBKED3	24S50B	24F50B	SBD50
250	SEE30FX250A	IEE30MC250A	SMBKFD3	24S44B	24F44B	SBD44
	SEE30FX250C	IEE30MC250C	SMBKFD3	24S44B	24F44B	SBD44
	SEE42FX250A	IEE42MC250A	SMBKFD3	24S50B	24F50B	SBD50
	SEE42FX250C	IEE42MC250C	SMBKFD3	24S50B	24F50B	SBD50
400	SEE42JD400A	IEE42MC400A	SMBKJD3	24S68B	24F68B	SBD68
	SEE42JD400C	IEE42MC400C	SMBKJD3	24S68B	24F68B	SBD68
600	SEE42LD600A	IEE42MC600A	SMBKLD3	24S68B	24F68B	SBD68
	SEE42LD600C	IEE42MC600C	SMBKLD3	24S68B	24F68B	SBD68

