

Long Barrel Copper Lug T&B Catalog Number:

54815BE

UPC Number:


78621018985

Status:

Active

Description:

Copper Two-Hole Lug - Straight Long Barrel - max 35KV, 3/0 AWG Wire, 1/4" Bolt Size, 3/4" Hole Spacing, Tin Plated Blind End, Orange 50

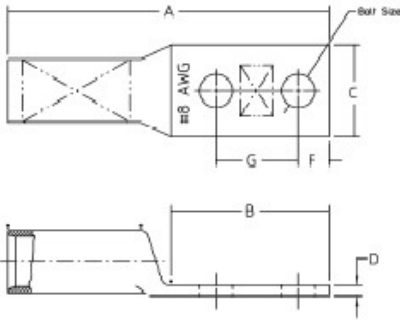

General

Material	Copper
Finish	Tin Plated
Wire Size	3/0 AWG
Number of Studs	2
Stud Size	1/4
Bolt Hole Spacing	3/4
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Orange
Die Code	50

Dimension Information

A (inches)	2.891
B (inches)	1.333
C (inches)	.938
D (inches)	.125
E (inches)	.625
F (inches)	.25
G (inches)	0.75

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

Package in Units	25
T&B Sold in UOM	Each
T&B Weight Per UOM	13 lbs. per 100

Application Support

T&B Instruction Sheets	ta01025-tb2
Product Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

Memphis, TN 38125
www.tnb.com

8155 T&B Blvd.
Memphis, TN 38125

Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com