

Long Barrel Aluminum Lug T&B Catalog Number:

60144

UPC Number:


78621060144

Status:

Active

Description:

Aluminum One-Hole Lug - Straight Long Barrel - max 35KV, 3/0 AWG Wire, 1/2" Bolt Size, Tin Plated Blind End, Ruby 60

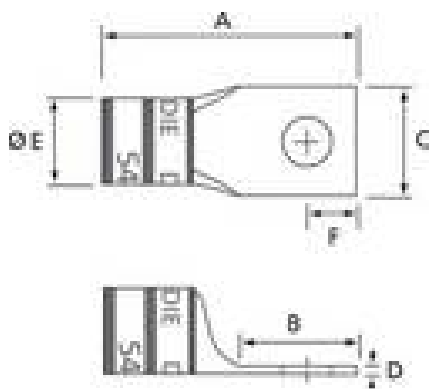

General

Material	Aluminum
Finish	Tin Plated
Wire Size	3/0 AWG
Number of Studs	1
Stud Size	1/2
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Ruby
Die Code	60

Dimension Information

A (inches)	3.15
B (inches)	1.41
C (inches)	1.06
D (inches)	.22
E (inches)	.77
F (inches)	.69

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Order Multiple	5
T&B Inner Pack	5
Package in Units	50
T&B Sold in UOM	Each
T&B Weight Per UOM	9.63 lbs. per 100

Application Support

T&B Instruction Sheets	ta00880-tb2
Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com