



Standard Barrel Copper Lug

T&B Catalog Number:

54206

UPC Number:

78621054206

Status:

Active

Description:

Copper Two-Hole Lug - Straight Standard Barrel - max 35KV, #4 AWG Wire, 1/4" Bolt Size, 5/8" Hole Spacing, Tin Plated with Inspection Hole, Grey 29

General

Material	Copper
Finish	Tin Plated
Wire Size	#4 AWG
Number of Studs	2
Stud Size	1/4
Bolt Hole Spacing	5/8
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Grey
Die Code	29

Dimension Information

A (inches)	2.031
B (inches)	1.172
C (inches)	.516
D (inches)	.094
E (inches)	.359
F (inches)	.25
G (inches)	0.625

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Inner Pack	50
Package in Units	500
T&B Sold in UOM	Each
T&B Weight Per UOM	2.99 lbs. per 100

Application Support


T&B Instruction Sheets	ta00675-tb2
Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

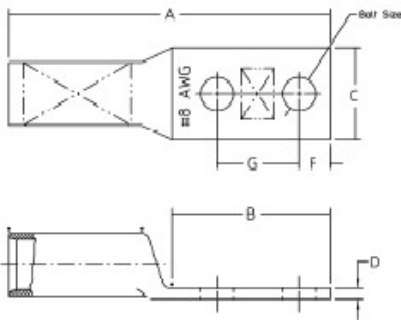

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com