

## Long Barrel Copper Lug T&B Catalog Number:

54814BE

**UPC Number:**


78621018984

**Status:**

Active

**Description:**

Copper Two-Hole Lug - Straight Long Barrel - max 35KV, 2/0 AWG Wire, 1/4" Bolt Size, 5/8" Hole Spacing, Tin Plated Blind End, Black 45

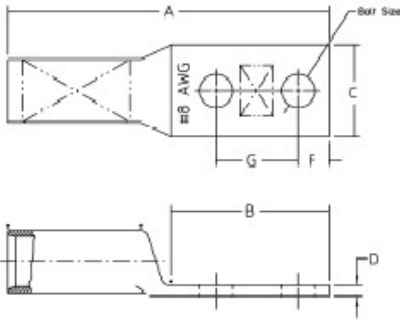

### General

Material	Copper
Finish	Tin Plated
Wire Size	2/0 AWG
Number of Studs	2
Stud Size	1/4
Bolt Hole Spacing	5/8
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Black
Die Code	45

### Dimension Information

A (inches)	2.516
B (inches)	1.234
C (inches)	.828
D (inches)	.125
E (inches)	.578
F (inches)	.25
G (inches)	0.625

### Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

### Packaging

T&B Order Multiple	5
T&B Inner Pack	5
Package in Units	25
T&B Sold in UOM	Each
T&B Weight Per UOM	11.19 lbs. per 100

### Application Support

Product Overview	Available on Website
------------------	----------------------

### Notes

Dimensions given for reference only. Dimensions may vary up to .030.

### Certifications

RoHS Compliance	Yes
-----------------	-----

**For further technical assistance, please contact us...**

8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)