


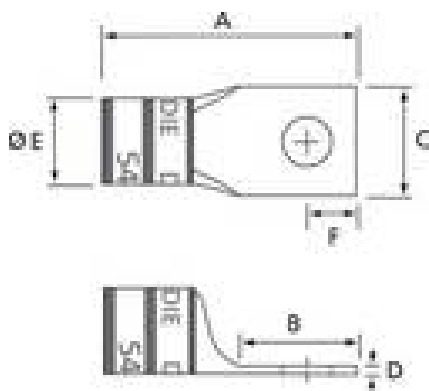

Standard Barrel Copper Lug

T&B Catalog Number:

UPC Number:

54162-TB

Status:

78621054162

Description:

Active

Copper One-Hole Lug - Straight Standard Barrel - max 35KV, 3/0 AWG Wire, 1/4" Bolt Size, Tin Plated with Inspection Hole, Orange 50

General

Material	Copper
Finish	Tin Plated
Wire Size	3/0 AWG
Number of Studs	1
Stud Size	1/4
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Orange
Die Code	50

Dimension Information

A (inches)	1.75
B (inches)	0.65
C (inches)	0.92
D (inches)	0.13
E (inches)	0.63
F (inches)	0.25

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Order Multiple	10
T&B Inner Pack	10
Package in Units	100
T&B Sold in UOM	Each
T&B Weight Per UOM	7.25 lbs. per 100

Application Support

T&B Instruction Sheets	ta00675-tb2
Product Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.

T&B Technical Support
MS 3B-50

Hours: 7AM - 6PM CDT
Monday-Friday

Memphis, TN 38125
www.tnb.com

8155 T&B Blvd.
Memphis, TN 38125

Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com