

Long Barrel Copper Lug

T&B Catalog Number:

54819BE

UPC Number:


78621019472

Status:

Active

Description:

Copper Two-Hole Lug - Straight Long Barrel - max 35KV, 300 kcmil Wire, 3/8" Bolt Size, 1" Hole Spacing, Tin Plated Blind End, White 66

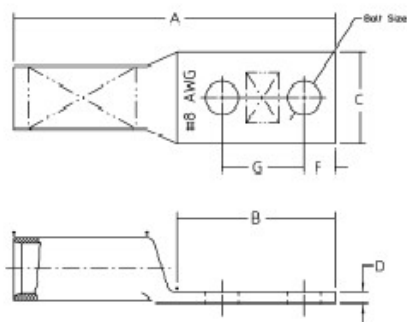

General

Material	Copper
Finish	Tin Plated
Wire Size	300 kcmil
Number of Studs	2
Stud Size	3/8
Bolt Hole Spacing	1
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	White
Die Code	66

Dimension Information

A (inches)	5
B (inches)	2.781
C (inches)	1.25
D (inches)	.156
E (inches)	.844
F (inches)	.375
G (inches)	1

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Order Multiple	2
T&B Inner Pack	2
Package in Units	10
T&B Sold in UOM	Each
T&B Weight Per UOM	37.88 lbs. per 100

Application Support

T&B Instruction Sheets	ta01025-tb2
Product Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com