

**Standard Barrel Copper Lug**

**T&B Catalog Number:**

54275

**UPC Number:**


78621054275

**Status:**

Active

**Description:**

Copper Two-Hole Lug - Straight Standard Barrel - max 35KV, 250 kcmil Wire, 1/2" Bolt Size, 1 3/4" Hole Spacing, Tin Plated with Inspection Hole, Yellow 62

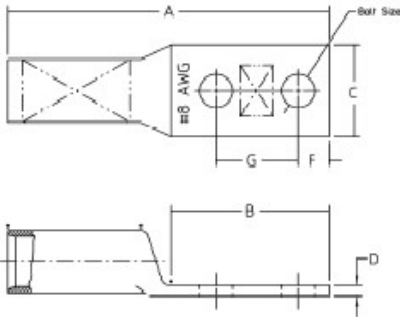

**General**

Material	Copper
Finish	Tin Plated
Wire Size	250 kcmil
Number of Studs	2
Stud Size	1/2
Bolt Hole Spacing	1 3/4
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Yellow
Die Code	62

**Dimension Information**

A (inches)	4.188
B (inches)	2.813
C (inches)	1.094
D (inches)	.188
E (inches)	.766
F (inches)	.5
G (inches)	1.75

**Specifications**

Voltage Rating	600V to 35KV
----------------	--------------

**Tooling**

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

**Packaging**

T&B Order Multiple	10
T&B Inner Pack	10
Package in Units	100
T&B Sold in UOM	Each
T&B Weight Per UOM	20.43 lbs. per 100

**Application Support**

T&B Instruction Sheets	ta00884-tb2
Overview	Available on Website

**Notes**

Dimensions given for reference only. Dimensions may vary up to .030.

**Certifications**

RoHS Compliance Yes

## Certifications



File Nbr:  
E9809

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)