

Standard Barrel Copper Lug

T&B Catalog Number:

54131

UPC Number:


78621054131

Status:

Active

Description:

Copper One-Hole Lug - Straight Standard Barrel - max 35KV, #8 AWG Wire, 5/16" Bolt Size, Tin Plated with Inspection Hole, Red 21

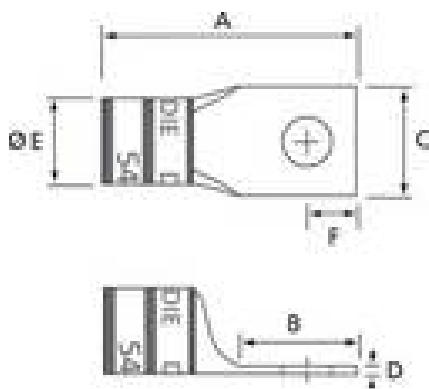

General

Material	Copper
Finish	Tin Plated
Wire Size	#8 AWG
Number of Studs	1
Stud Size	5/16
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Red
Die Code	21

Dimension Information

A (inches)	1.33
B (inches)	0.64
C (inches)	0.56
D (inches)	0.05
E (inches)	0.27
F (inches)	9/32

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Inner Pack	50
Package in Units	500
T&B Sold in UOM	Each
T&B Weight Per UOM	1.13 lbs. per 100

Application Support

T&B Instruction Sheets	ta00675-tb2
Product Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125

T&B Technical Support
MS 3B-50
8155 T&B Blvd.

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289

