
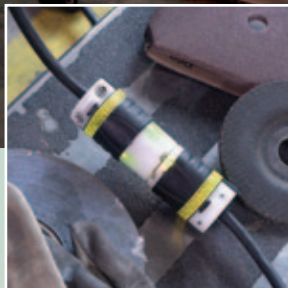


P&S

Straight Blade Plugs & Connectors

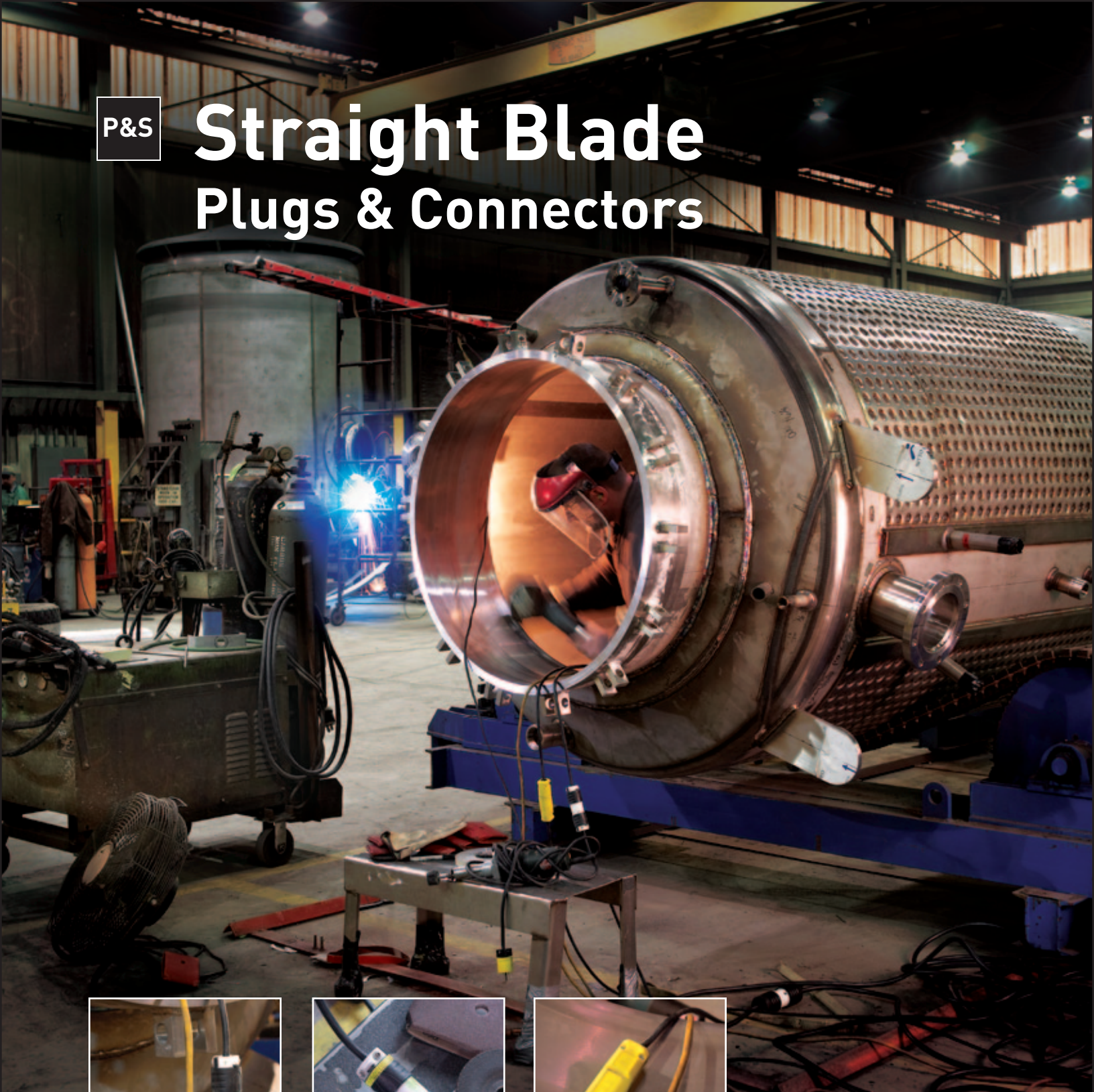

designed to be better.

 **legrand**[®]

Pass & Seymour

Extreme durability runs in the family.

Count on
rock-solid
reliability.

Look at our complete line of quality plugs and connectors, and you'll see durability everywhere. In our choice of premium materials. In robust, uncompromising construction. And, most of all, in designs based on decades of feedback from contractors and MRO professionals. P&S Plugs & Connectors are built to deliver consistent, high performance. To provide years of dependable service in your toughest real-world conditions. And to bring you maximum value.

See for yourself.

Quick-thread assembly screws and cord-grip screws come backed out and ready to wire.

See-through, thermo-plastic terminal chamber for clear views of terminals and wire connections.

Tapered wire wells guide conductors in to captive, staked clamping nuts.

Keyed housing for fast alignment with terminal section.


Chemical- and impact-resistant nylon housing features horizontal, comfort-grip back body.

Industrial-strength, brass alloy plug blades and connector contacts resist heat rise and provide excellent conductivity. Reinforced ground pin adds strength and safety.

Color-coded terminal screws are positioned on the same plane and backed out for fast, reliable installation.

Double-wipe, firm-grip ground contact and triple-wipe power contacts guarantee superior connections.


Rugged, external, two-piece cord grip with offset jaws provides uniform pressure for superior conductor retention.

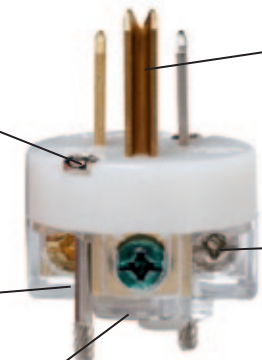

PS5266-X



PS5269-X

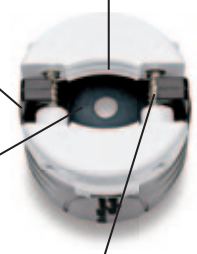

Recessed cord-grip screw reduces screwdriver slippage and enhances safety.

Internal dust shield keeps terminals free of contaminants.

#8 cord-grip screws permit higher torque for a more secure installation.

Dead Front Plugs & Connectors

- Reliable choices for residential and light commercial tool and extension cord use
- Twist-on back body for fast, no-screw assembly
- Open terminal provides visual confirmation of correct termination
- Integral screw-clamp cord grip speeds installation



5276-BK



4867-Y

Medium-Duty Plugs & Connectors


- Pick these strong performers for residential and light commercial tool and extension cord use, portable lighting and business machines
- Screw-fastened back body ensures reliable assembly
- Open terminal provides visual confirmation of correct termination
- Clamping cord grip provides excellent conductor retention

MaxGrip® M³ Plugs & Connectors

- Excellent for commercial use with tools, extension cords, lighting, vending machines and light machinery
- Tough, nylon construction delivers crush and impact resistance that exceeds hospital grade and Fed Spec requirements
- Self-hinge body swings wide open to enable fast, tight, clean connections
- Enclosed terminals provide solid, internally clamped connections
- Molded finger grips promote safe, sure handling




PS5965-Y

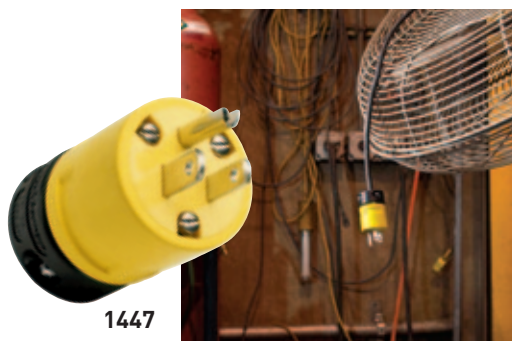

1447

Rubber Dust-Tight Plugs & Connectors

- Rugged choices for commercial or industrial dry outdoor use with shop tools and extension cords
- Rubber dust-tight body provides chemical resistance
- Enclosed terminals protect against contaminants and resist wire splaying
- Clamping cord grip provides excellent conductor retention

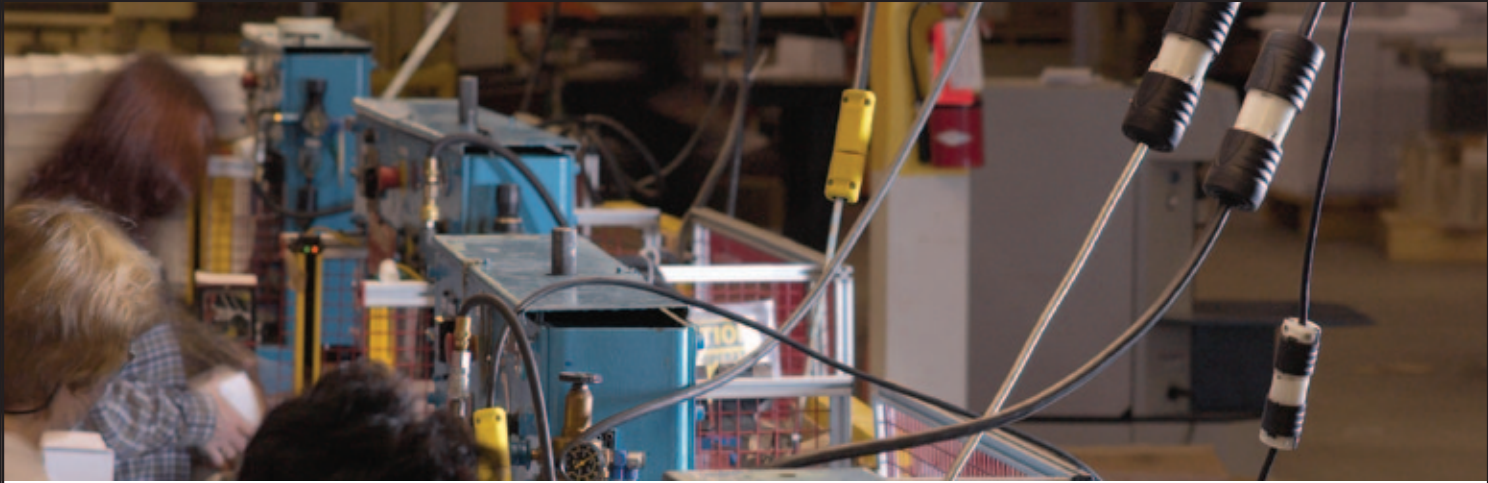


Extra-Hard Use Specification Grade Plugs & Connectors

- Get superior durability in commercial and industrial use — a great choice for tools, extension cords, machines and lighting
- Tri-drive terminal screws are backed out, ready to wire for fast, easy installation
- Nylon housing for superior impact and chemical resistance
- Heavy-duty brass alloy blades and contacts provide excellent conductivity
- Rugged, two-piece offset jaw cord grip provides superior conductor retention
- Internal dust shield keeps terminals free of contaminants



PS5266-X

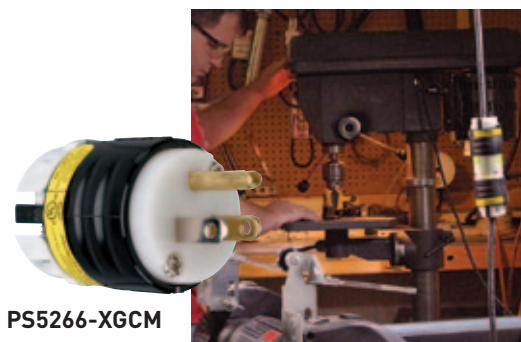

PS5266-XGCM

Extra-Hard Use Ground Continuity Monitoring (GCM) Plugs & Connectors

- Superior durability in commercial and industrial use
- Integral, continuous ground continuity and power-status indication enhances safety
- Green LEDs indicate proper ground continuity; red LEDs signal ground continuity loss or reversed polarity

Rubber Watertight Plugs & Connectors

- Rugged performers for commercial or industrial wet indoor or outdoor use with shop tools, machines and extension cords
- Rubber dust- and water-tight body provides chemical resistance
- Enclosed terminals protect against contaminants and resist wire splaying
- Watertight compression cord grip provides superior protection against ingress of solid and liquid contaminants



14W47*

* Shown with 14WPS Protective Cap — cap sold separately

P&S Straight Blade Plugs & Connectors

IP20
Suitability



PS5266-X



PS5269-X



PS5266-SSAN



PS5266-XHG



PS5269-XHG



PS5266-XGCM



PS5269-XGCM




5276-BK

Catalog Number	Rating A.	Rating V.	Description	NEMA Config. No.
Extra-Hard Use (EHU) – Specification Grade^{††} (Cord Diameter .230" – .720")				
PS5266-X*	15	125	Plug, Black & Gray	5-15P
CR5266-X	15	125	Plug, Corrosion-Resistant, Yellow & White	5-15P
PS5269-X*	15	125	Connector, Black & Gray	5-15R
CR5269-X	15	125	Connector, Corrosion-Resistant, Yellow & White	5-15R
PS5366-X	20	125	Plug, Black & White	5-20P
PS5369-X	20	125	Connector, Black & White	5-20R
PS5666-X	15	250	Plug, Black & White	6-15P
PS5669-X	15	250	Connector, Black & White	6-15R
PS5466-X	20	250	Plug, Black & White	6-20P
PS5469-X	20	250	Connector, Black & White	6-20R
PS5766-X	15	277	Plug, Black & White	7-15P
PS5866-X	20	277	Plug, Black & White	7-20P
Extra-Hard Use (EHU) – Specification Grade Angle Plugs^{††} (Cord Diameter .320" – .655")				
PS5266-SSAN	15	125	Plug, Black & White	5-15P
PS5366-SSAN	20	125	Plug, Black & White	5-20P
PS5666-SSAN	15	250	Plug, Black & White	6-15P
PS5466-SSAN	20	250	Plug, Black & White	6-20P

Extra-Hard Use (EHU) – Hospital Grade^{††} (Cord Diameter .230" – .720")				
PS5266-XHG	15	125	Plug, Black & Clear	5-15P
PS5269-XHG	15	125	Connector, Black & Clear	5-15R
PS5366-XHG	20	125	Plug, Black & Clear	5-20P
PS5369-XHG	20	125	Connector, Black & Clear	5-20R
PS5666-XHG	15	250	Plug, Black & Clear	6-15P
PS5669-XHG	15	250	Connector, Black & Clear	6-15R
PS5466-XHG	20	250	Plug, Black & Clear	6-20P
PS5469-XHG	20	250	Connector, Black & Clear	6-20R
Extra-Hard Use (EHU) – Hospital Grade Angle Plugs^{††} (Cord Diameter .320" – .655")				
PS5266-HGAN	15	125	Plug, Black & Clear	5-15P
PS5366-HGAN	20	125	Plug, Black & Clear	5-20P
PS5666-HGAN	15	250	Plug, Black & Clear	6-15P
PS5466-HGAN	20	250	Plug, Black & Clear	6-20P

Extra-Hard Use (EHU) – Ground Continuity Monitoring (GCM)^{††} (Cord Diameter .230" – .720")				
PS5266-XGCM	15	125	Plug, Black & Clear	5-15P
PS5269-XGCM	15	125	Connector, Black & Clear	5-15R
PS5366-XGCM	20	125	Plug, Black & Clear	5-20P
PS5369-XGCM	20	125	Connector, Black & Clear	5-20R
PS5666-XGCM	15	250	Plug, Black & Clear	6-15P
PS5669-XGCM	15	250	Connector, Black & Clear	6-15R
PS5466-XGCM	20	250	Plug, Black & Clear	6-20P
PS5469-XGCM	20	250	Connector, Black & Clear	6-20R

Dead Front (Cord Diameter .230" – .655")				
5276-BK	15	125	Plug, Black	5-15P
5269-BK	15	125	Connector, Black	5-15R
5765-BK	20	125	Plug, Black	5-20P
5374-BK	20	125	Connector, Black	5-20R
5666-BK	15	250	Plug, Black	6-15P
5669-BK	15	250	Connector, Black	6-15R
5864-BK	20	250	Plug, Black	6-20P
5866-BK	20	250	Connector, Black	6-20R

 

All devices listed on this page conform to NEMA WD-1 and WD-6

† UL[®] Compliant
† FSUL WC596 Compliant

* Available in Gray (add GRY to part #)
or Black (add BK to part #) interior.

† Cord Diameter .385"-1.150"

P&S Straight Blade Plugs & Connectors



4867-Y



PS5965-Y



PS5965-O



PS5969-Y



PS5969-O



1447



14W47

Catalog Number	Rating		Description	NEMA Config. No.
	A.	V.		
Medium-Duty[†] (Cord Diameter .250" - .600")				
4867-Y	15	125	Plug, Yellow	5-15P
4887-Y	15	125	Connector, Yellow	5-15R

Hospital Grade MaxGrip[®] M³** (Cord Diameter .230" - .720")				
PS8115-GRY	15	125	Hospital Grade Plug, Gray	5-15P
PS8119-GRY	15	125	Hospital Grade Connector, Gray	5-15R
MaxGrip M³† (Cord Diameter .230" - .720")				
PS5965-Y	15	125	Plug, Yellow	5-15P
PS5965-GRY	20	125	Plug, Gray	5-20P
PS5965-IG	15	125	Plug, Orange, for use with equipment restricted to isolated ground receptacles	5-15P
PS5965-O	15	125	Plug, Orange	5-15P
PS5965-BK	15	125	Plug, Black	5-15P
PS5969-Y	15	125	Connector, Yellow	5-15R
PS5969-GRY	15	125	Connector, Gray	5-15R
PS5969-O	15	125	Connector, Orange	5-15R
PS5969-BK	15	125	Connector, Black	5-15P
PS5364-Y [‡]	20	125	Plug, Yellow	5-20P
PS5364-GRY [‡]	20	125	Plug, Gray	5-20P
PS5369-Y [‡]	20	125	Connector, Yellow	5-20R
PS5369-GRY [‡]	20	125	Connector, Gray	5-20R
PS5666-Y [‡]	15	250	Plug, Yellow	6-15P
PS5669-Y [‡]	15	250	Connector, Yellow	6-15R
PS5464-Y [‡]	20	250	Plug, Yellow	6-20P
PS5469-Y [‡]	20	250	Connector, Yellow	6-20R

IP20
Suitability

Rubber Dust-Tight (Cord Diameter .335" - .640")				
1447	15	125	Plug, Rubber Yellow	5-15P
1547	15	125	Connector, Rubber Yellow	5-15R
1433P	20	125	Plug, Rubber Yellow	5-20P
1533	20	125	Connector, Rubber Yellow	5-20R
1449	15	250	Plug, Rubber Yellow	6-15P
1549	15	250	Connector, Rubber Yellow	6-15R
1448	20	250	Plug, Rubber Yellow	6-20P
1548	20	250	Connector, Rubber Yellow	6-20R
Watertight (Cord Diameter .062" - .625")				
14W47	15	125	Plug, Black	5-15P
15W57	15	125	Connector, Black	5-15R
14W33	20	125	Plug, Black	5-20P
15W33	20	125	Connector, Black	5-20R
14W49	15	250	Plug, Black	6-15P
15W49	15	250	Connector, Black	6-15R
14W48	20	250	Plug, Black	6-20P
15W58	20	250	Connector, Black	6-20R

All devices listed on this page conform to NEMA WD-1 and WD-6

[†] eUL_{us} Compliant
[‡] FSUL WC596 Compliant

For additional technical or application-specific information, call 800-223-4185 or visit our website at www.legrand.us/passandseymour. We're eager to put our expertise to work for you.

Distributed by:

Legrand/Pass & Seymour
P.O. Box 4822
Syracuse, NY 13221-4822
800-776-4035
www.legrand.us/passandseymour



North America Headquarters
60 Woodlawn Street
West Hartford, CT 06110
Phone: 1.877.BY.LEGRAND (295.3472)
Fax: 1.860.232.2062
www.legrand.us

Legrand Canada
570 Applewood Crescent
Vaughan, ON, L4K 4B4
Phone: 905.738.9195
Fax: 905.738.9721
www.legrand.ca