

Long Barrel Copper Lug

T&B Catalog Number:

54922BE

UPC Number:

78621019481

Status:

Active

Description:

Copper One-Hole Lug - Straight Long Barrel - max 35KV, 750 kcmil Wire, 1/2" Bolt Size, Tin Plated Blind End, Black 106

General

Material	Copper
Finish	Tin Plated
Wire Size	750 kcmil
Number of Studs	1
Stud Size	1/2
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Black
Die Code	106

Dimension Information

A (inches)	4.344
B (inches)	1.234
C (inches)	1.938
D (inches)	.266
E (inches)	1.328
F (inches)	.5

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Order Multiple	2
T&B Inner Pack	2
Package in Units	10
T&B Sold in UOM	Each
T&B Weight Per UOM	75 lbs. per 100

Application Support


T&B Instruction Sheets	ta01025-tb2
Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

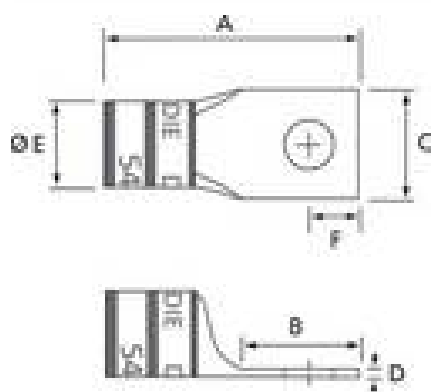

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com