


Bar Hangers and Brackets

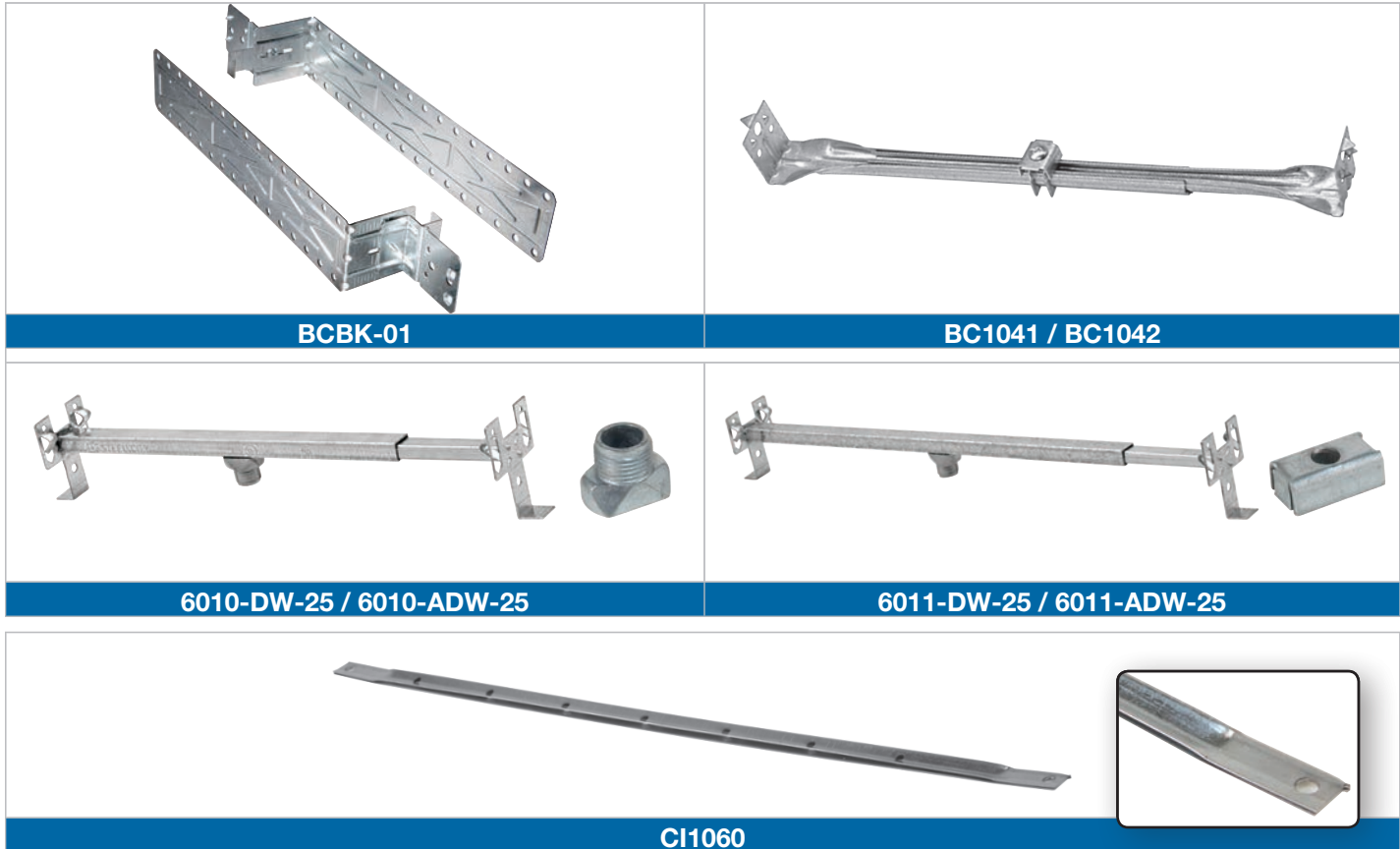

Cat. No.	Description
<b>Bar Hangers</b>	
<b>BCBK-01</b>	Adjustable hanger for wood stud. Length: 15.5 in. Height: 2.5 in.
<b>BC1041</b>	Adjustable from 11-1/2 in. to 18-1/2 in. Maximum load capacity: 50 lb. (22.7)
<b>BC1042</b>	Adjustable from 16-1/2 in. to 26-1/2 in. When extended up to 22-1/2 in. 50 lb. (22.7). When extended up to 26-1/2 in. 25 lb. (11.35)
<b>Adjustable Bar Hangers for Plaster and Drywall — Depth 1-3/16 in.</b>	
<b>6010-DW-25<sup>†</sup></b>	For 3/8 in., 1/2 in. and 5/8 in. wall board and plaster. Score marks for drywall and plaster depths. Maximum load capacity: 50 lb. (22.7). Length: 10-1/2 in. to 18-1/2 in. Packaged complete with stud
<b>6010-ADW-25<sup>†</sup></b>	For 3/8 in., 1/2 in. and 5/8 in. wall board and plaster. Score marks for drywall and plaster depths. Maximum load capacity: 50 lb. (22.7). Length: 14-1/2 in. to 26-1/2 in. Packaged complete with stud
<b>6011-DW-25<sup>†</sup></b>	For 3/8 in., 1/2 in. and 5/8 in. wall board and plaster. Score marks for drywall and plaster depths. Maximum load capacity: 50 lb. (22.7). Length: 10-1/2 in. to 18-1/2 in. Packaged complete with fastener
<b>6011-ADW-25<sup>†</sup></b>	For 3/8 in., 1/2 in. and 5/8 in. wall board and plaster. Score marks for drywall and plaster depths. Maximum load capacity: 50 lb. (22.7). Length: 14-1/2 in. to 26-1/2 in. Packaged complete with fastener
<b>Support Brackets</b>	
<b>CI1060</b>	Length: 16 in. Grooved for box ears