

Polyester Modular Enclosures - NEMA 4X

PJU Series - Viewing Window Door

Application


- Designed for use as instrument enclosures, electric, hydraulic or pneumatic control housings, electrical junction boxes or terminal wiring enclosures.
- Provides outstanding insulation and protection where equipment may be hosed down or be very wet.
- Ideal in applications with high temperatures or highly corrosive environments.

Panel Sold Separately



Standards

- UL 508 Type 1, 2, 3, 4, 4X, 12 and 13
- CSA Type 1, 2, 3, 4, 4X, 12 and 13
- Complies with
 - NEMA Type 1, 2, 3, 4, 4X, 12 and 13
 - IEC 529, IP66

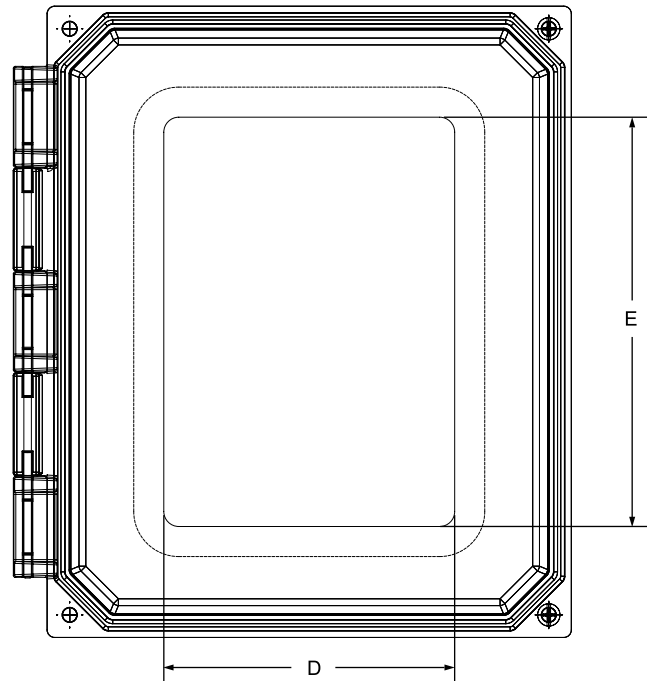

- High UV resistant Polycarbonate Viewing Window
- Factory installed
- Maintains Nema 4X ratings

Corrosion Resistant

Wallmount Enclosures

Part No.	Overall Dimensions			Viewing Window	
	Height	Width	Depth	D	E
PJU664*3	6.05	6.27	4.13	3.50	3.50
PJU864*3	8.05	6.27	4.13	4.00	5.25
PJU1084*1	10.05	8.27	4.13	4.25	6.25
PJU12106*1	12.05	10.27	6.13	6.50	8.38
PJU14126*2	14.05	12.27	6.13	8.50	10.38
PJU16148*3	16.05	14.27	8.13	10.50	12.38
PJU181610*4	18.30	16.52	10.13	11.00	13.00
PJU201610*4	20.50	16.27	10.13	12.00	14.00

1 Available 4th Qtr 2006
3 Available 2nd Qtr 2007

2 Available 1st Qtr 2007
4 Available 3rd Qtr 2007

* see chart below for full part number & latch including mounting feet

Lift Off Viewing Window Flange	Lift Off Viewing Window Feet	Hinged Screw Cover Viewing Window Flange	Hinged Screw Cover Viewing Window Feet	Hinged Snap Latch Viewing Window Flange	Hinged Snap Latch Viewing Window Feet	Hinged Twist Latch Viewing Window Flange	Hinged Twist Latch Viewing Window Feet
PJU664WF	PJU664W	PJU664HWF	PJU664HW	PJU664LWF	PJU664LW	PJU664TWF	PJU664TW
PJU864WF	PJU864W	PJU864HWF	PJU864HW	PJU864LWF	PJU864LW	PJU864TWF	PJU864TW
PJU1084WF	PJU1084W	PJU1084HWF	PJU1084HW	PJU1084LWF	PJU1084LW	PJU1084TWF	PJU1084TW
PJU12106WF	PJU12106W	PJU12106HWF	PJU12106HW	PJU12106LWF	PJU12106LW	PJU12106TWF	PJU12106TW
PJU14126WF	PJU14126W	PJU14126HWF	PJU14126HW	PJU14126LWF	PJU14126LW	PJU14126TWF	PJU14126TW
PJU16148WF	PJU16148W	PJU16148HWF	PJU16148HW	PJU16148LWF	PJU16148LW	PJU16148TWF	PJU16148TW
PJU181610WF	PJU181610W	PJU181610HWF	PJU181610HW	PJU181610LWF	PJU181610LW	PJU181610TWF	PJU181610TW
PJU201610WF	PJU201610W	PJU201610HWF	PJU201610HW	PJU201610LWF	PJU201610LW	PJU201610TWF	PJU201610TW

Technical references and DXF downloads available at www.hammmfg.com

All dimensions in inches unless specified otherwise