

Metal Clad Cable Termination Fittings & Accessories

T&B Catalog Number:

STEX400

UPC Number:


78621099678

Status:

Active

Description:

Star Teck Extreme hazardous location aluminum jacketed cable fitting, hub size-4 in.

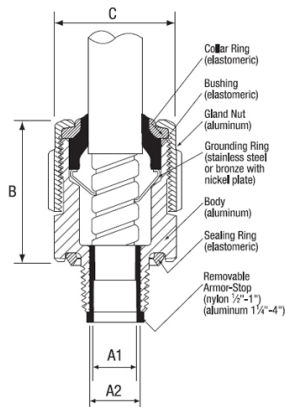

Features

- Patented powergrip grounding ring.
- Removable armor-stop for greater cable ranges.
- Patented elastomeric collar ring/busing for greater cable ranges.
- Built-in jacket stripping gauge on gland nut.
- Gland nut can be tightened with hammer and screwdriver.

Application

- Provides means for passing armored, metal clad, jacketed cable through a bulkhead or enclosure in hazardous areas. (these fittings are suitable for hazardous areas when used with T&B sealing compound).
- Form a mechanical grip and water and/or oil-resistant termination.
- Provide grounding continuity of cable armor.

General

Material	Aluminum
Strip Length (inches)	2 1/2
Sealing Compound Required-Putty (grams)	1323
Sealing Compound Required-Liquid (cc)	636

Dimension Information

Hub Size (inches)	4
Dimension B (inches)	7.650
Dimension C (inches)	6.190
A1:Throat Diameter Minimum (w/Armor Stop)	3.055
A2:Throat Diameter Minimum (wo/Armor Stop)	3.461
Range Over Jacket -Minimum (inches)	3.220
Range Over Jacket -Maximum (inches)	3.870
Range Over Armor -Minimum (inches)	3.090
Range Over Armor -Maximum (inches)	3.640
Strip Length (inches)	2 1/2

Packaging

Package in Units	1
T&B Sold in UOM	Each
T&B Weight Per UOM	4.5 lbs. Each

Application Support

Product Specifications & Overview	Available on Website
-----------------------------------	----------------------

Notes

*Note

Fittings are suitable for hazardous areas when used with T&B sealing compound.

Certifications

RoHS Compliance Yes

Certifications



File Nbr:
E 82038

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com