



Ferrule
T&B Catalog Number:

F4020
 78621033674
 Active

UPC Number:
Status:
Description:


Insulated Nylon OLD DIN Style Ferrule for Wire Size 14, Wire Size 2.5 mm², Length 0.571 inches, Blue

WEB_USE

US Cutsheet PDF Catalog Link <http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

Ferrules ensure reliable electrical connections when terminating conductors in screw clamp terminal blocks.

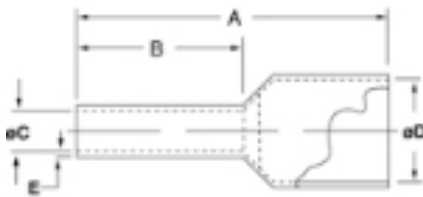

General

Ferrule Type	OLD DIN
Insulation Type	Insulated Nylon
Material	Copper
Finish	Electro -Tin Plated
Color	Blue
Wire Range	14
Wire Size (mm ²)	2.50

Dimension Information

A (mm)	14.5
B (mm)	8.0
Diameter C (inches)	.091
Diameter C (mm)	2.3
Diameter D (inches)	.165
Diameter D (mm)	4.2
E (mm)	.15
A (inches)	.571
B (inches)	.315
E (inches)	.006

Specifications

Temperature Rating	105°C
Flammability Rating	UL 94 V-2

Tooling

Tool Charts	Available on Website
Application Tools	T1, T3, ERG4
Recommended Tool	T1, T3, ERG4

Packaging

T&B Order Multiple	500
T&B Inner Pack	500
Package in Units	10000
T&B Sold in UOM	Each
T&B Weight Per UOM	0.63 lbs. per 1000

Application Support

T&B Sales Drawings	wsd-000402
Overview	Available on Website

Wire Guide Tables

Available on Website

Notes

Ferrule dimensions conform to DIN 46228, Part 4.

Certifications

RoHS Compliance

Yes

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com