



**Ring Terminal**  
**T&B Catalog Number:**

RB14-8X  
 78621080410  
 Active

**UPC Number:**  
**Status:**  
**Description:**


Expanded Insulated Nylon Ring Terminal For Wire Range 18-14 Stud Size #8, Blue

**WEB\_USE**

US Cutsheet PDF Catalog Link <http://www-public.tnb.com/contractor/docs/stakon.pdf>

**Features**

Catalog numbers ending with the suffix X indicate an expanded insulation grip. This means a wider wire entry to accommodate heavy wall insulation. Ring terminals won't fall free even if the mounting screw loosens.

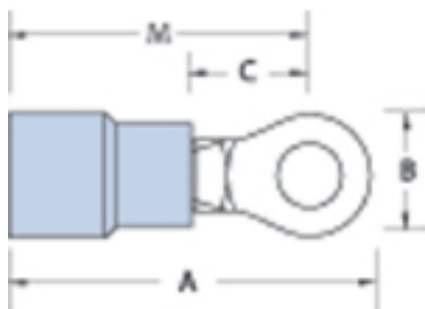

**General**

Insulation Type	Expanded Insulated Nylon
Terminal Series	RB
Material	Copper
Finish	Electro -Tin Plated
Color	Blue
Wire Range	18-14
Stud Size	#8

**Dimension Information**

Maximum Insulation (inches)	.190
Stock Thickness	.03
A (inches)	.95
B (inches)	.31
C (inches)	.25
M (inches)	.79

**Specifications**

Temperature Rating	105°C
Voltage Rating	600V
Flammability Rating	UL 94 V-2

**Tooling**

Tool Charts	Available on Website
Application Tools	WT2000, WT112M, WT145C, ERG4001, ERG4003, WT145A
Recommended Tool	ERG4001

**Packaging**

T&B Order Multiple	100
T&B Inner Pack	100
Package in Units	500
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	0.29 lbs. per 100
Alternate Package Qty	RB864

**Application Support**

Overview	Available on Website
Wire Guide Tables	Available on Website

## Certifications

RoHS Compliance	Yes
-----------------	-----

## Certifications



File Nbr:  
E9809

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email:techsupport@tnb.com