

Standard Barrel Copper Lug

T&B Catalog Number:

54280

UPC Number:


78621054280

Status:

Active

Description:

Copper Two-Hole Lug - Straight Standard Barrel - max 35KV, 300 kcmil Wire, 1/2" Bolt Size, 1 3/4" Hole Spacing, Tin Plated with Inspection Hole, White 66

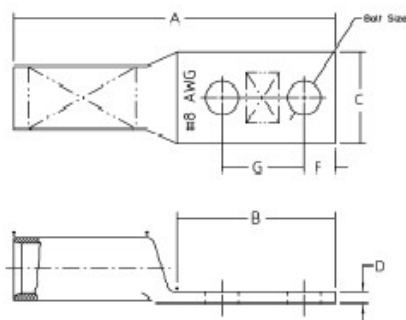

General

Material	Copper
Finish	Tin Plated
Wire Size	300 kcmil
Number of Studs	2
Stud Size	1/2
Bolt Hole Spacing	1 3/4
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	White
Die Code	66

Dimension Information

A (inches)	4.453
B (inches)	3
C (inches)	1.25
D (inches)	.156
E (inches)	.844
F (inches)	.5
G (inches)	1.75

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Order Multiple	10
T&B Inner Pack	10
Package in Units	100
T&B Sold in UOM	Each
T&B Weight Per UOM	26 lbs. per 100

Application Support

T&B Instruction Sheets	ta00884-tb2
Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance Yes

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com