

Long Barrel Aluminum Lug
T&B Catalog Number:

60271

UPC Number:


78621060271

Status:

Active

Description:

Aluminum Two-Hole Lug - Straight Long Barrel - max 35KV, 500 kcmil Wire, 3/8" Bolt Size, 1" Hole Spacing, Tin Plated Blind End, Pink 99H

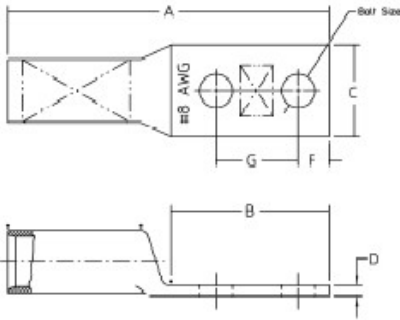

General

Material	Aluminum
Finish	Tin Plated
Wire Size	500 kcmil
Number of Studs	2
Stud Size	3/8
Bolt Hole Spacing	1
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Pink
Die Code	99H

Dimension Information

A (inches)	5.63
B (inches)	1.93
C (inches)	1.79
D (inches)	.38
E (inches)	1.28
F (inches)	.38
G (inches)	1

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Order Multiple	2
T&B Inner Pack	2
Package in Units	20
T&B Sold in UOM	Each
T&B Weight Per UOM	40 lbs. per 100

Application Support

T&B Sales Drawings	wsd-000581
T&B Instruction Sheets	ta00880-tb2
Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance Yes

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com