



Industrial grade AC toggle switches

Product description


Single-pole, double-pole, 3-way, 4-way
 15A, 120/277V/AC; 15A, 347V/AC
 20A, 120/277V/AC; 20A, 347V/AC; 30A, 120/277V/AC

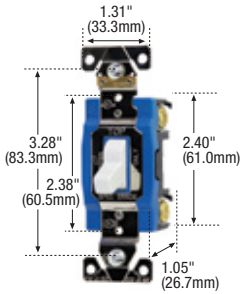


AH1201

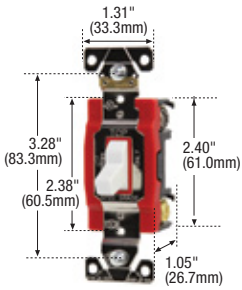

AH1223

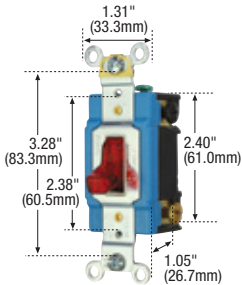

AH1201PL

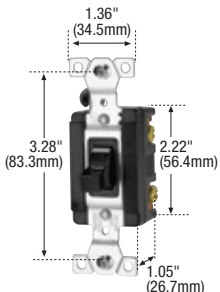

AH18201

Premium industrial grade AC toggle switches, back & side wire



Rating	A	V/AC	Description	Color suffix	Catalog no.				
15	120/277		Single-pole, toggle	B, GY, RD, V, W	<input type="checkbox"/> AH1201__	•	•	•	•
			Double-pole toggle	B, GY, V, W	<input type="checkbox"/> AH1202__	•	•	•	•
			3-Way, toggle	B, GY, RD, V, W	<input type="checkbox"/> AH1203__	•	•	•	•
			4-Way, toggle	B, GY, V, W	<input type="checkbox"/> AH1204__	•	•	•	•
20	120/277		Single-pole, toggle	B, BK, GY, LA, RD, V, W	<input type="checkbox"/> AH1221__	•	•	•	•
			Double-pole toggle	B, GY, RD, V, W	<input type="checkbox"/> AH1222__	•	•	•	•
			3-Way, toggle	B, BK, GY, LA, RD, V, W	<input type="checkbox"/> AH1223__	•	•	•	•
			4-Way, toggle	B, BK, GY, LA, RD, V, W	<input type="checkbox"/> AH1224__	•	•	•	•
30	120/277		Single-pole, toggle	B, RD, V, W	<input type="checkbox"/> 3031__*	•	•	•	•
			Double-pole toggle	B, RD, V, W	<input type="checkbox"/> 3032__*	•	•	•	•

* Not NOM cert

Industrial grade AC lighted toggle switches, back & side wire



Rating	A	V/AC	Description	Color suffix	Catalog no.				
15	120/277		Single-pole, lighted toggle	V, W	<input type="checkbox"/> AH1201LT__	•	•	•	•
			3-Way, lighted toggle	V, W	<input type="checkbox"/> AH1203LT__	•	•	•	•
			Single-pole, pilot lighted red toggle	RD	<input type="checkbox"/> AH1201PL	•	•	•	•
20	120/277		Double-pole, pilot lighted red toggle	RD	<input type="checkbox"/> AH1202PL	•	•	•	•
			Single-pole, lighted toggle	V, W	<input type="checkbox"/> AH1221LT__	•	•	•	•
			3-Way, lighted toggle	V, W	<input type="checkbox"/> AH1223LT__	•	•	•	•
20	120/277		Single-pole, pilot lighted red toggle	RD	<input type="checkbox"/> AH1221PL	•	•	•	•
			Double-pole, pilot lighted red toggle	RD	<input type="checkbox"/> AH1222PL	•	•	•	•
			30	120/277	Double-pole, pilot lighted red toggle	RD	<input type="checkbox"/> 3032PL*	•	•

* Not NOM cert

Industrial grade AC toggle switches, back & side wire



Rating	A	V/AC	Description	Color suffix	Catalog no.				
15	347		Single-pole, Canadian voltage toggle	B, I, W	<input type="checkbox"/> AH18201__«	•	•	•	•
			Double-pole, Canadian voltage toggle	B, I	<input type="checkbox"/> AH18202__«	•	•	•	•
			3-Way, Canadian voltage toggle	B, I, W	<input type="checkbox"/> AH18203__«	•	•	•	•
20	347		Single-pole, Canadian voltage toggle	B, I, W	<input type="checkbox"/> AH18221__«	•	•	•	•
			Double-pole, Canadian voltage toggle	B, I	<input type="checkbox"/> AH18222__«	•	•	•	•
			3-Way, Canadian voltage toggle	B, I, W	<input type="checkbox"/> AH18223__«	•	•	•	•

« No Color suffix = Brown, I = Ivory

Color ordering information:

For ordering devices, include Catalog no. Followed by the Color suffix: B (Brown), BK (Black), GY (Gray), LA (Light Almond), RD (Red), V or I (Ivory), W (White)



Specification information: 120/277V Industrial: E-36, 120/277V industrial ArrowLink modular: E-43

Compliances, specifications and availability are subject to change without notice.

ArrowLink option available. Add "M" suffix to Standard catalog number (example AH1201B, AH1201BM). For ordering information on ArrowLink & ArrowLink SPD connectors, see Page E-4

Build-to-spec customizable devices - Page E-6

Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32

www.eaton.com

www.eaton.com/arrowhart