
**TECHNICAL READOUT**

Catalog No.	Capacity Per Block	Ground Strip	Hub Top Entry	Size
BPS100	1-1/0 to 14 6-2 to 14	3 x (4-14)	-	14" x 8 7/8" x 4"
BPS200	1-300 MCM 6-2/0 to 14	3 x (4-14)	-	14" x 11 1/2" x 4"
VFB100	4-2/0 to 14	3 x (4-14)	1 1/4"	11" x 8" x 4 1/4"
VFB200	2-300MCM 3-2/0 to 14	3 x (4-14)	2"	11" x 8" x 4 1/4" 18" x 12" x 5 3/8"

**Application:**

Type 3R enclosure designed for indoor/outdoor distribution.

**Construction:**

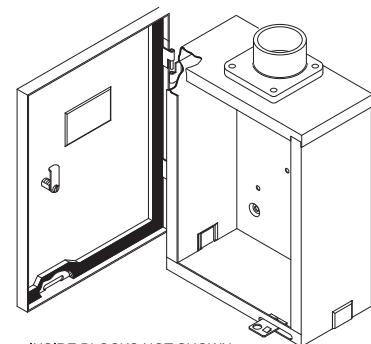
- BPS: ungasketed sliding cover
- VFB: gasketed slip hinged cover
- Retractable sealing hasp
- Both models supplied with three (3) blocks and one (1) Grounding strip
- 16 galvanized steel gauge Natural Finish

**Also Available:**

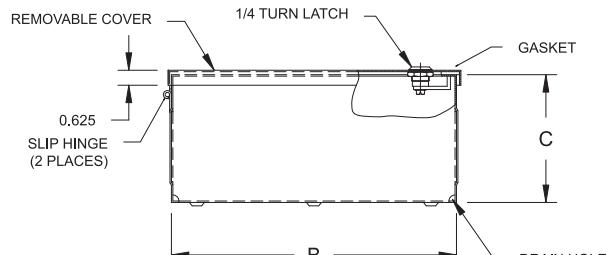
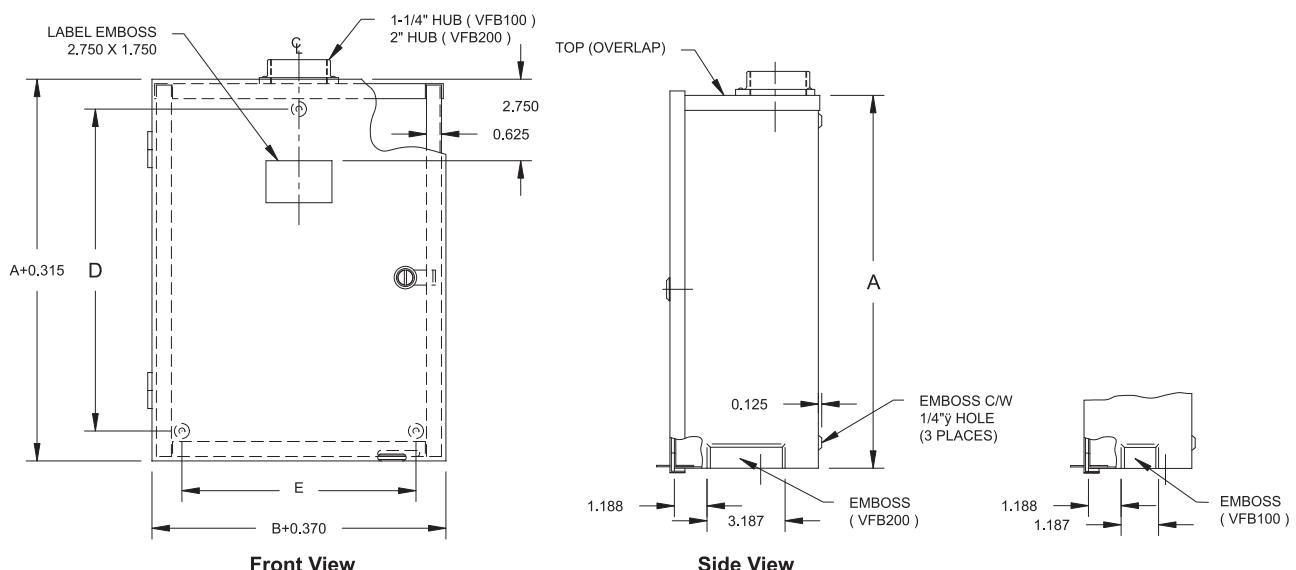
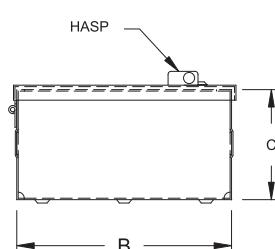
- Cutouts, louvers and hubs
- Aluminium, SS, galvanized steel
- Special finishes & sizes

**Standards:**

- CSA certified 150359



INSIDE BLOCKS NOT SHOWN

Bottom View  
VFB200Bottom View  
VFB100

## TECHNICAL READOUT

Catalog No.	A	B	C	D	E
VFB100	11.060	8.094	4.220	8.438	5.844
VFB200	18.000	11.880	5.325	13.875	7.875