



**C-Tap**  
**T&B Catalog Number:**


54715  
 78621054715  
 Active

**UPC Number:**  
**Status:**  
**Description:**

Copper C-Tap for Wire Range Main: 6-8, Branch 8-12, Gray 29

**Features**

- Positive, all-around compression with low resistance and high pull-out values.
- Ideal for pigtailing, 2-way splicing or tapping to an unbroken continuous main.
- Heavy reinforcing ribs help locate compression dies and strengthen compressed joint.

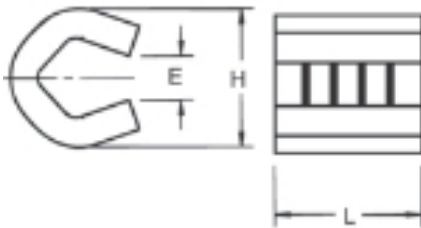

**General**

Style	Standard
Material	Copper
Finish	Plain
Wire Size	6-8
Die Color	Gray
Die Code	29

**Dimension Information**

H (inches)	5/8
L (inches)	9/16

**Specifications**

Voltage Rating	600V
----------------	------

**Accessories & Components**

Shrink Tubing	HS126
Soft Shell Cover	HTCV1

**Tooling**

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

**Packaging**

T&B Inner Pack	100
Package in Units	500
T&B Sold in UOM	Each
T&B Weight Per UOM	1.3 lbs. per 100

**Application Support**

T&B Instruction Sheets	ta00628-tb2
------------------------	-------------

**Notes**

- Each C-Tap contains a range of conductor sizes. See Installation Instructions for wire range combinations.
- UL approved for direct burial.
- Taps can be supplied tin-plated. Add suffix TP to any catalog number.

**Certifications**

RoHS Compliance	Yes
-----------------	-----

## Certifications



File Nbr:  
140B

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)