

## Standard Barrel Copper Lug

T&B Catalog Number:

54286

UPC Number:


78621054286

Status:

Active

Description:

Copper Two-Hole Lug - Straight Standard Barrel - max 35KV, 500 kcmil Wire, 1/2" Bolt Size, 1 3/4" Hole Spacing, Tin Plated with Inspection Hole, Brown 87

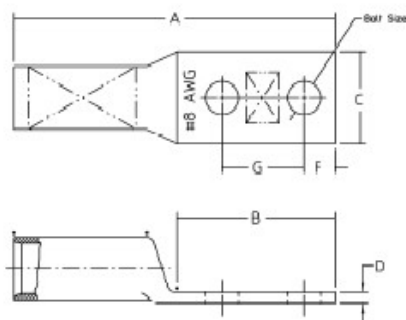

### General

Material	Copper
Finish	Tin Plated
Wire Size	500 kcmil
Number of Studs	2
Stud Size	1/2
Bolt Hole Spacing	1 3/4
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Brown
Die Code	87

### Dimension Information

A (inches)	5
B (inches)	3
C (inches)	1.609
D (inches)	.219
E (inches)	1.109
F (inches)	.5
G (inches)	1.75

### Specifications

Voltage Rating	600V to 35KV
----------------	--------------

### Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

### Packaging

T&B Order Multiple	6
T&B Inner Pack	6
Package in Units	60
T&B Sold in UOM	Each
T&B Weight Per UOM	56.69 lbs. per 100

### Application Support

T&B Instruction Sheets	ta00884-tb2
Overview	Available on Website

### Notes

Dimensions given for reference only. Dimensions may vary up to .030.

### Certifications

RoHS Compliance Yes

## Certifications



File Nbr:  
E9809

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)